


# Case Style

# HL

## Outline Dimensions

## HL1162

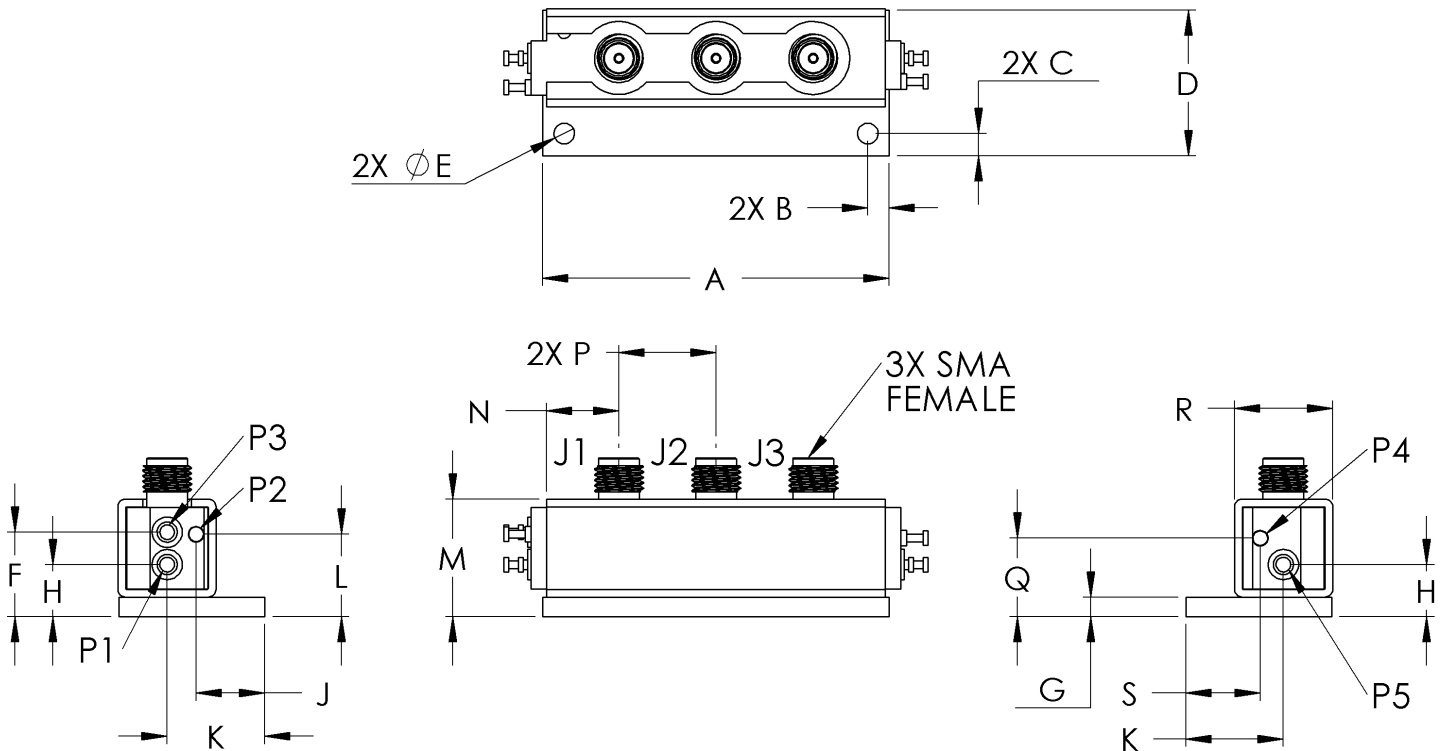

CASE #.	A	B	C	D	E	F	G	H	J	K	L	M	N
HL1162	1.782 (45.26)	.110 (2.79)	.115 (2.92)	.750 (19.05)	.106 (2.69)	.435 (11.04)	.100 (2.54)	.268 (6.79)	.353 (8.97)	.502 (12.75)	.424 (10.76)	.605 (15.37)	.371 (9.42)

CASE #.	P	Q	R	S	WT GRAMS
HL1162	.500 (12.70)	.404 (10.25)	.505 (12.83)	.383 (9.73)	56

**Dimensions are in inches (mm). Tolerances: 2Pl. ± .03; 3Pl. ± .015**  
**Tolerance on hole size and interaxes dimensions to be ± .005.**

### Note:

1. Case material: Brass
2. Case finish: Nickel plate

**Mini-Circuits®**

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661