


### Outline Dimensions

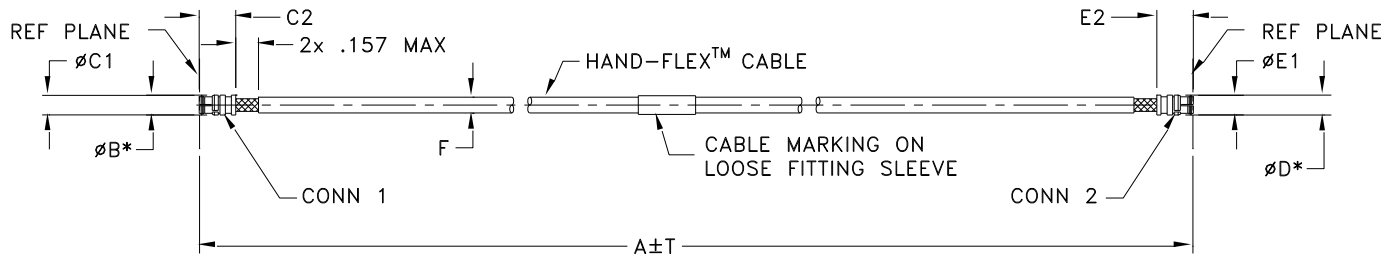

\* OVERALL CONNECTOR DIMENSION [CONNECTOR SHAPE MAY VARY]

**KP2093 SERIES**  
**SMP FEMALE (CONN-1)**  
**SMP FEMALE (CONN-2)**

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		G	H	T		WEIGHT GRAMS
	INCH	MM							086U-ASMP+	086-ASMP+			INCH	MM	
KP2093-6	6.00	152.40	.14 (3.50)	.135 (3.43)	.252 (6.40)	.14 (3.50)	.135 (3.43)	.252 (6.40)	.091 MAX (2.31 MAX)	.123 MAX (3.12 MAX)	--	--	.05	1.27	3.24
KP2093-10	10.00	254.00									--	--	.10	2.54	5.07
KP2093-12	12.00	304.80									--	--	.10	2.54	5.98

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

**Note:**

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" represents length of cable.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified