


## Outline Dimensions

KP3378

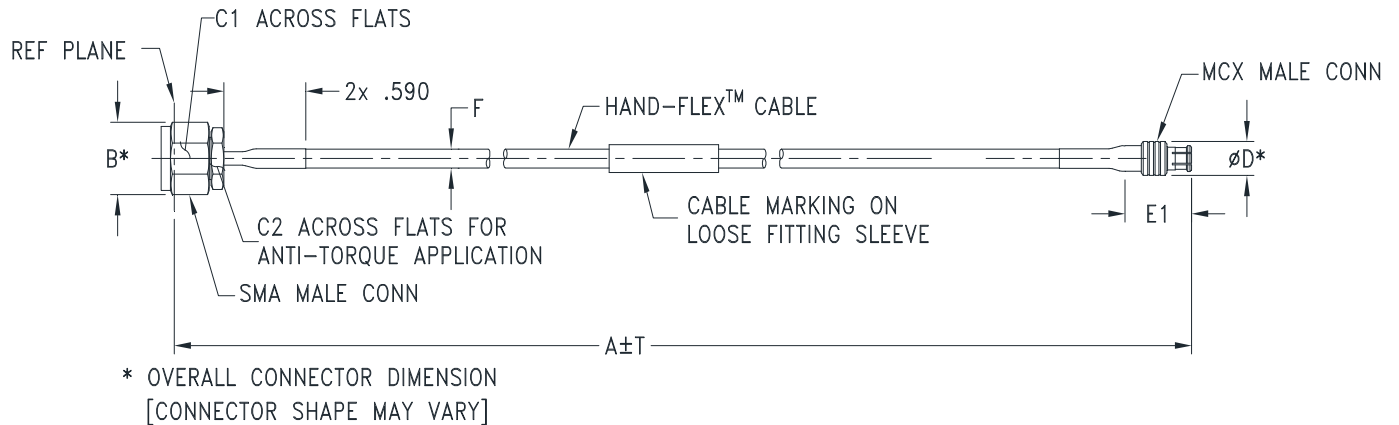

KP3378 SERIES  
SMA MALE (CONN-1)  
MCX MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		T		WEIGHT GRAMS
	INCH	MM							086U-ASMMC+	086-ASMMC+	INCH	MM	
KP3378-8	8.00	203.20	.36 [9.14]	.315 [8.00]	.250 [6.35]	.197 [5.00]	.480 [12.2]	-	.089 ± .002 [2.26 ± .05]	.108 NOM [2.74 NOM]	.10	2.54	8.36
KP3378-12	12.00	304.80									.10	2.54	10.18

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

### Note:

- 086 Hand-Flex™ Coaxial Cable.
- "A" represents length of cable.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified