


Outline Dimensions

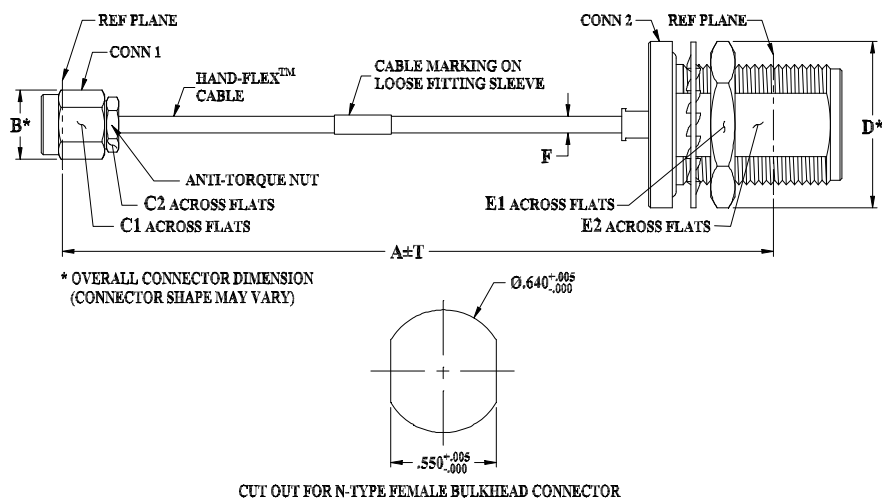

KQ1669 SERIES
SMA MALE (CONN-1)
N FEMALE BULKHEAD (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		T		WEIGHT GRAMS
	INCH	MM							141U-ASMNB+	141-ASMNB+	INCH	MM	
KQ1669-3	3.00	76.20	.36 (9.14)	.313 (7.95)	.250 (6.35)	.87 (22.10)	.750 (19.05)	.531 (13.49)	.141±.003 (3.58±0.07)	.163±.004 (4.14±0.10)	.05	1.27	44.73
KQ1669-4	4.00	101.60									.05	1.27	45.87
KQ1669-5	5.00	127.00									.05	1.27	47.02
KQ1669-6	6.00	152.40									.05	1.27	48.16
KQ1669-7	7.00	177.80									.10	2.54	49.30
KQ1669-8	8.00	203.20									.10	2.54	50.44
KQ1669-9	9.00	228.60									.10	2.54	51.59
KQ1669-10	10.00	254.00									.10	2.54	52.73
KQ1669-11	11.00	279.40									.10	2.54	53.87
KQ1669-12	12.00	304.80									.10	2.54	55.02
KQ1669-14	14.00	355.60							.15	3.81	57.30		
KQ1669-16	16.00	406.40							.15	3.81	59.59		
KQ1669-18	18.00	457.20							.15	3.81	61.87		
KQ1669-20	20.00	508.00							.15	3.81	64.16		
KQ1669-24	24.00	609.60							.15	3.81	68.73		
KQ1669-30	30.00	762.00							.20	5.08	75.59		
KQ1669-36	36.00	914.40							.20	5.08	82.45		

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

1. 141 Hand-Flex™ Coaxial Cable.
2. "A" represents length of cable.