


Case Style

KQ

Outline Dimensions

KQ1927

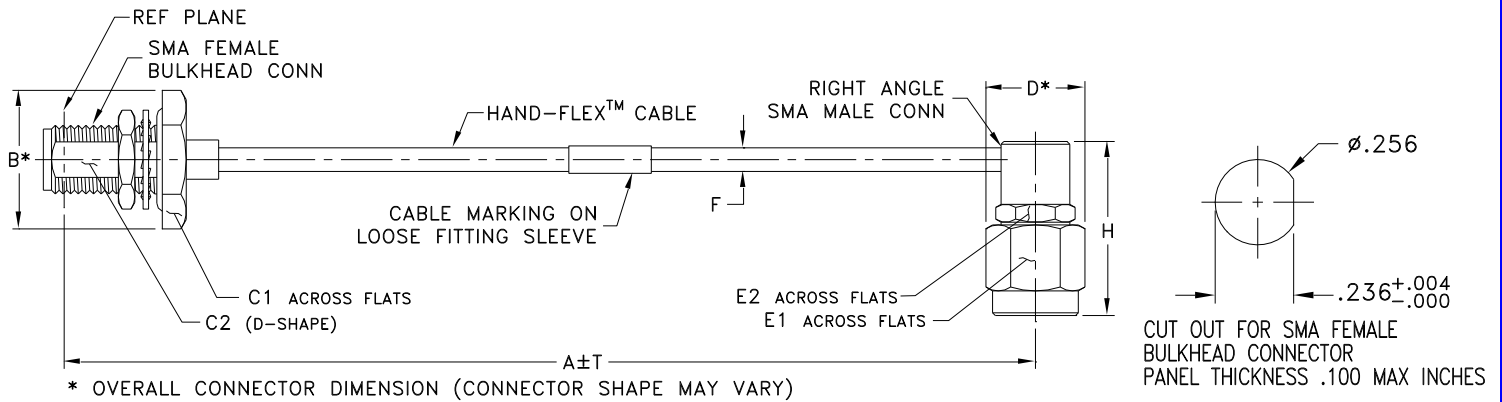

KQ1927 SERIES
 BULKHEAD SMA FEMALE(CONN-1)
 RIGHT ANGLE SMA MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		G	H	T		WEIGHT GRAMS
	INCH	MM							141U-ASBSMR+	141-ASBSMR+			INC H	MM	
KQ1927-6	6.00	152.40	.51 (12.95)	.438 (11.13)	.232 (5.89)	.36 (9.14)	.313 (7.95)	.250 (6.35)	.139±.002 (3.53±.05)	.163±NOM (4.14 NOM)	-	.728±.020 (18.50)	0.05	1.27	13.06
KQ1927-36	36.00	914.40											0.20	5.08	47.35

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

1. 141 Hand-Flex™ Coaxial Cable.
2. "A" represents length of cable.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/MICROWAVE COMPONENTS