


# Case Style

# NR

## Outline Dimensions

## NR2563

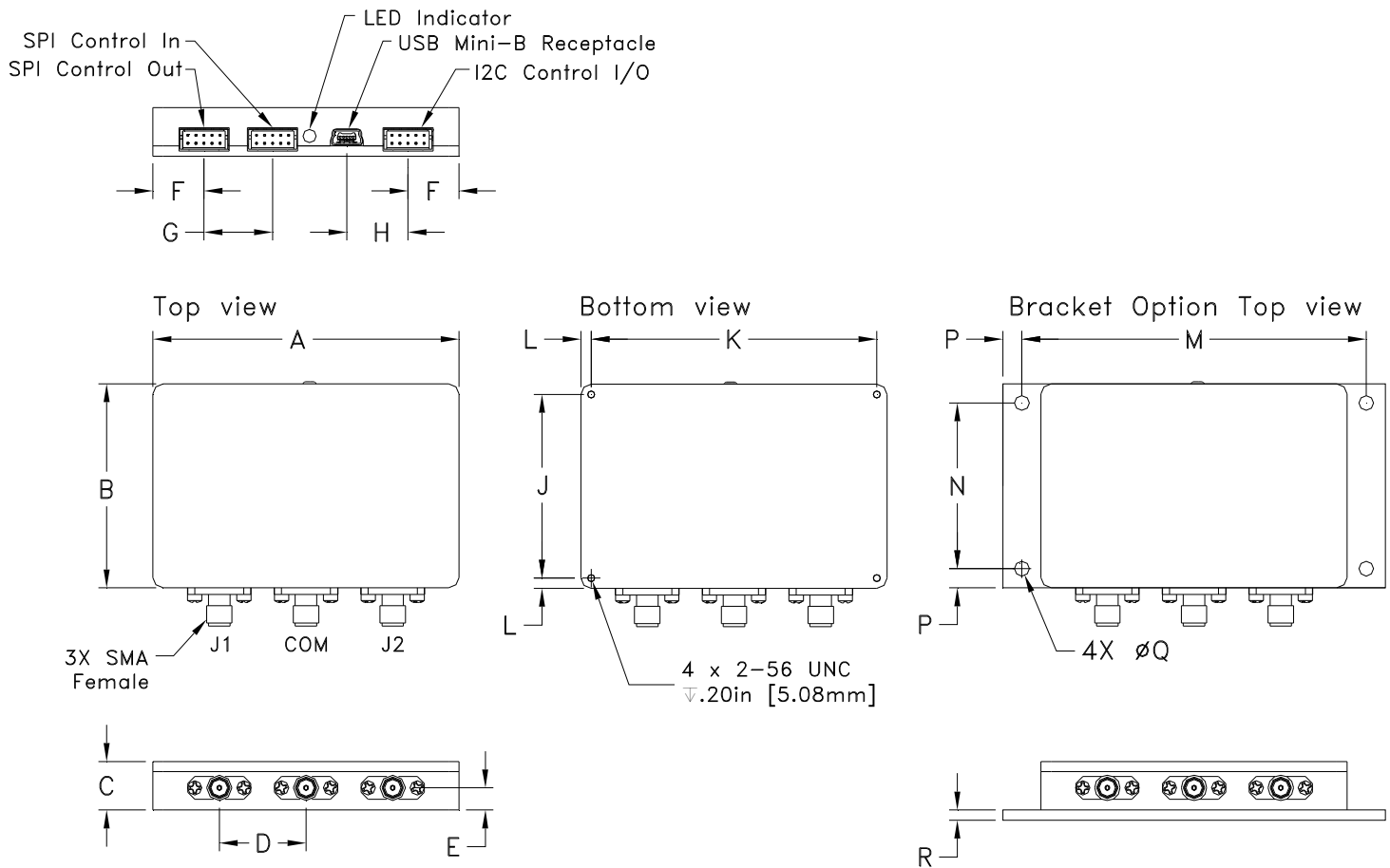

CASE#	A	B	C	D	E	F	G	H	J	K	L	M
NR2563	3.000 (76.20)	2.000 (50.80)	.475 (12.07)	.850 (21.59)	.217 (5.51)	.500 (12.70)	.672 (17.07)	.600 (15.24)	1.800 (45.72)	2.800 (71.12)	.100 (2.54)	3.375 (85.73)

CASE#	N	P	Q	R	WT. GRAMS
NR2563	1.625 (41.28)	.188 (4.77)	.144 (3.66)	.100 (2.54)	100

Dimensions are in inches (mm). Tolerances: 2PL. +/- .03; 3PL. +/- .015

### Notes:

1. Case material: Aluminum alloy.
2. Case finish for RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based

**Mini-Circuits**<sup>®</sup>

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified