


Outline Dimensions

NS2208

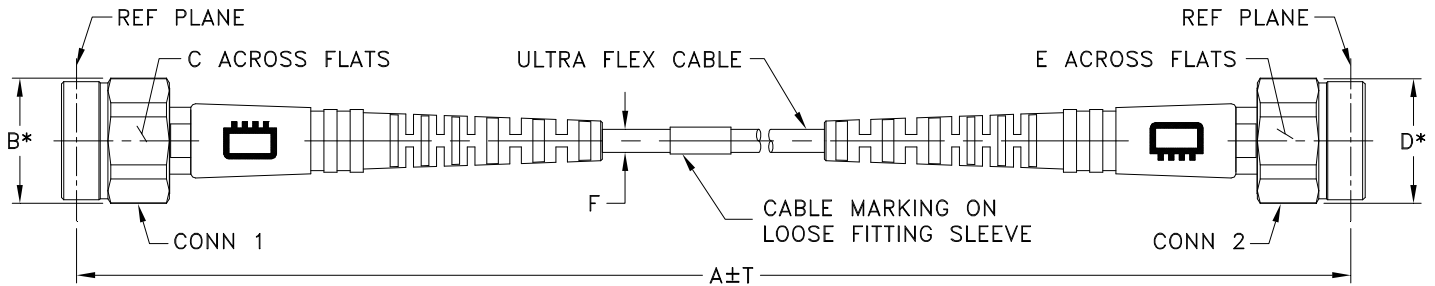

* OVERALL CONNECTOR/BOOT DIMENSION
[CONNECTOR/BOOT SHAPE MAY VARY]

NS2208 SERIES

N-Type MALE (CONN-1)

N-Type MALE (CONN-2)

CASE STYLE #	A		B	C	D	E	F	T		WEIGHT GRAMS
	FEET	METERS						FEET	METERS	
NS2208-2	2.00	0.61	.812 [20.62]	.750 [19.00]	.812 [20.62]	.750 [19.00]	.150±.004 [3.81±0.10]	.06	0.02	65
NS2208-3	3.00	0.91						.09	0.03	75
NS2208-3.28	3.28	1.00						.10	0.03	77
NS2208-4	4.00	1.22						.12	0.04	84
NS2208-6	6.00	1.83						.18	0.05	125
NS2208-10	10.00	3.05						.30	0.09	163

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

1. Ultra Flex Coaxial Cable.
2. "A" Represents Length of Cable.

Mini-Circuits®

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified