


Outline Dimensions

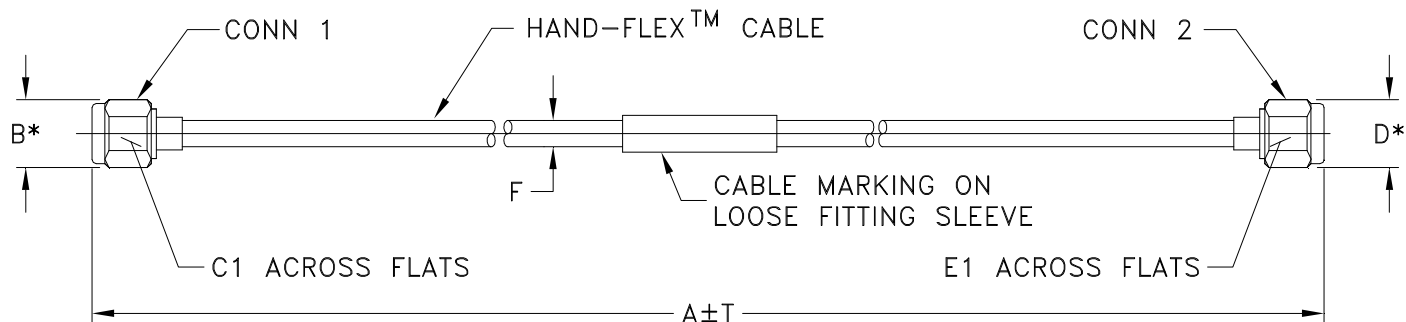

*OVERALL CONNECTOR OR CABLE & BOOT DIM
[CONNECTOR SHAPE MAY VARY]

RQ2535 SERIES

2.92mm MALE (CONN-1)

2.92mm MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F 086-AKM+	T		WEIGHT GRAMS
	INCH	MM								INCH	MM	
RQ2535-3	3.00	76.20	.36 (9.14)	.315 (8.00)	--	.36 (9.14)	.315 (8.00)	--	.104 (2.65)	.08	2.00	9.64
RQ2535-4	4.00	101.60								.08	2.00	10.19
RQ2535-6	6.00	152.40								.08	2.00	11.28
RQ2535-9	9.00	228.60								.08	2.00	12.92
RQ2535-12	12.00	304.80								.08	2.00	14.56
RQ2535-15	15.00	381.00								.15	3.81	16.21
RQ2535-18	18.00	457.20								.15	3.81	17.85
RQ2535-24	24.00	609.60								.15	3.81	21.13

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS