


# Case Style

# SE

## Outline Dimensions

## SE3051

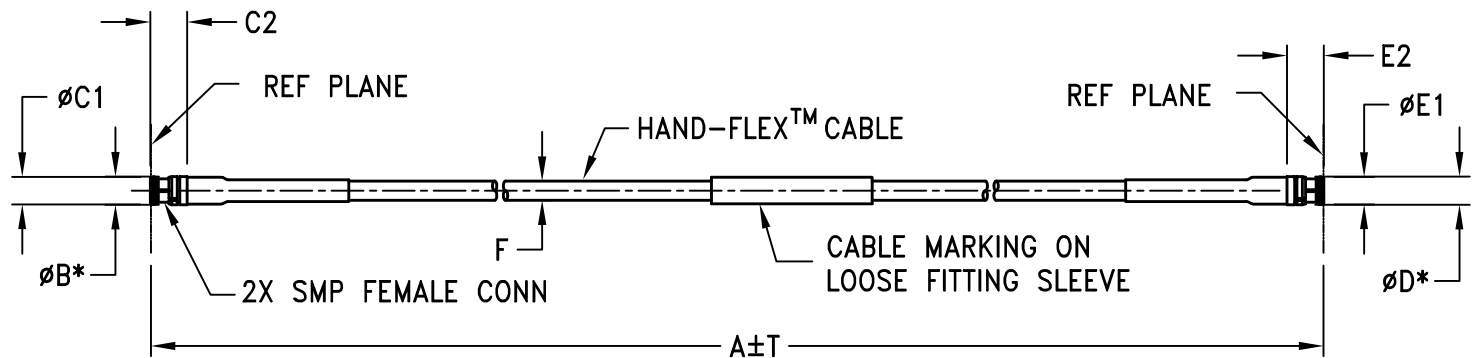

### SE3051 SERIES SSMP FEMALE (CONN)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F	T		WT. (GRAMS)
	INCH	MM							FL86-ASMP+	INCH	MM	
SE3051-12	12.00	304.80								.10	2.54	6.00
			.14	.135	.173	.14	.135	.173	.106±.004			
			[3.56]	[3.43]	[4.40]	[3.56]	[3.43]	[4.40]	[2.64±0.1]			

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2 Pl.±.03; 3 Pl. ±.015

Note:

1. 086 Flexible Coaxial Cable.
2. "A" Represents Length of Cable.

**Mini-Circuits®**  
ISO 9001 ISO 14001 CERTIFIED

ALL-NEW  
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS