


Case Style

SE

Outline Dimensions

SE3056

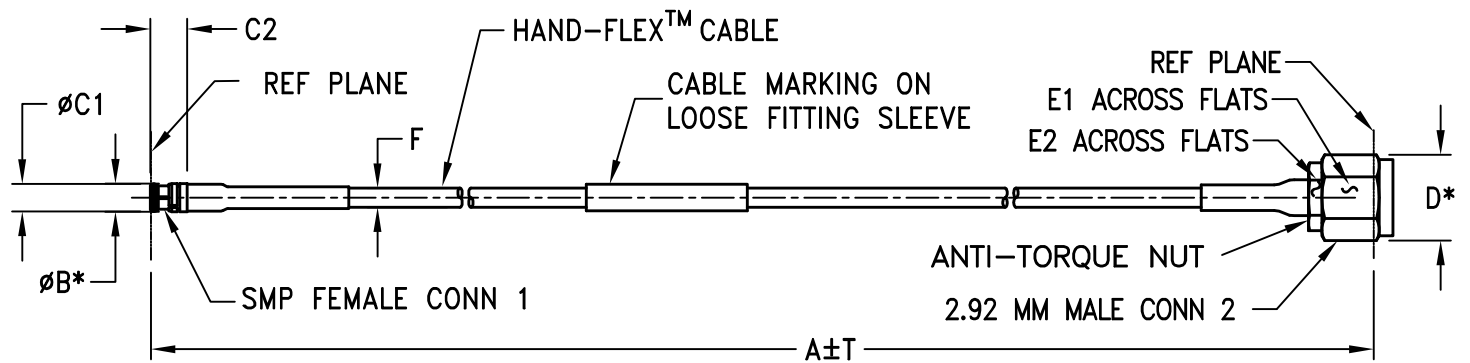

SE3056 SERIES

SMP FEMALE (CONN 1)

2.92 MM MALE (CONN 2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F	T		WT. (GRAMS)
	INCH	MM							FL86-ASMPKM+	INCH	MM	
SE3056-12	12.00	304.80								.10	2.54	9.00
			.14 [3.56]	.135 [3.43]	.173 [4.40]	.36 [9.14]	.315 [8.00]	.256 [6.50]	.106±.004 [2.64±0.1]			

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2 Pl. ±.03; 3 Pl. ±.015

Note:

- 086 Flexible Coaxial Cable.
- "A" Represents Length of Cable.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL-NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS