


# Case Style

# SE

## Outline Dimensions

## SE3058

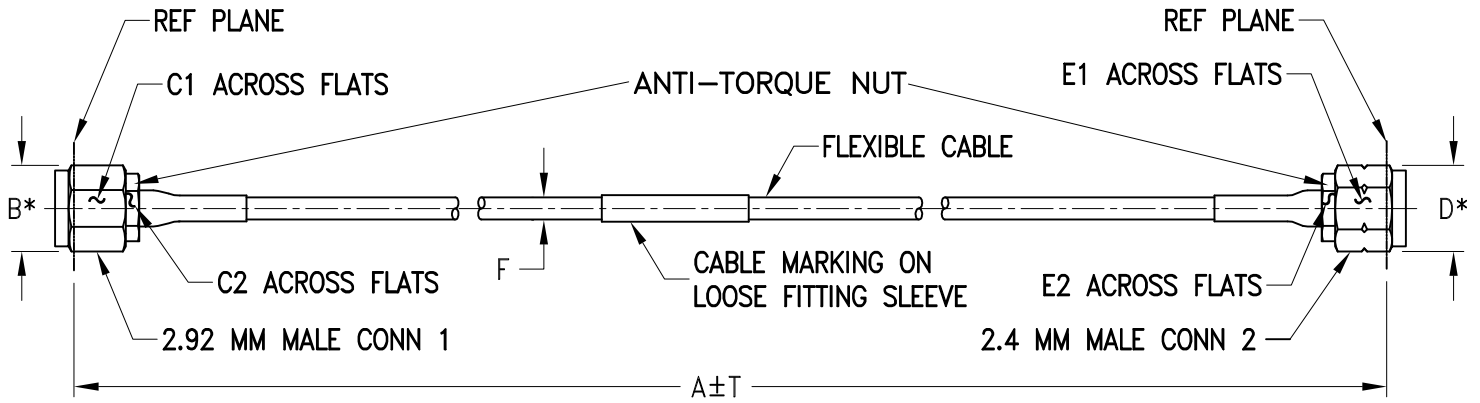

\* OVERALL CONNECTOR DIMENSION  
(CONNECTOR SHAPE MAY VARY)

### SE3058 SERIES

2.92 MM MALE (CONN 1)

2.4 MM MALE (CONN 2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F FL86-AKMVM+	T		WT. (GRAMS)
	INCH	MM								INCH	MM	
SE3058-12	12.00	304.80								.10	2.54	12.10
			0.36 [9.14]	.315 [8.00]	.256 [6.50]	.36 [9.14]	.315 [8.00]	.256 [6.50]	.106±.004 [2.64±0.1]			

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2 Pl. ±.03; 3 Pl. ±.015

Note:

1. 086 Flexible Coaxial Cable.
2. "A" Represents Length of Cable.

**Mini-Circuits®**  
ISO 9001 ISO 14001 CERTIFIED

ALL NEW  
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS