


# Case Style

# UU

## Outline Dimensions

UU2412-2

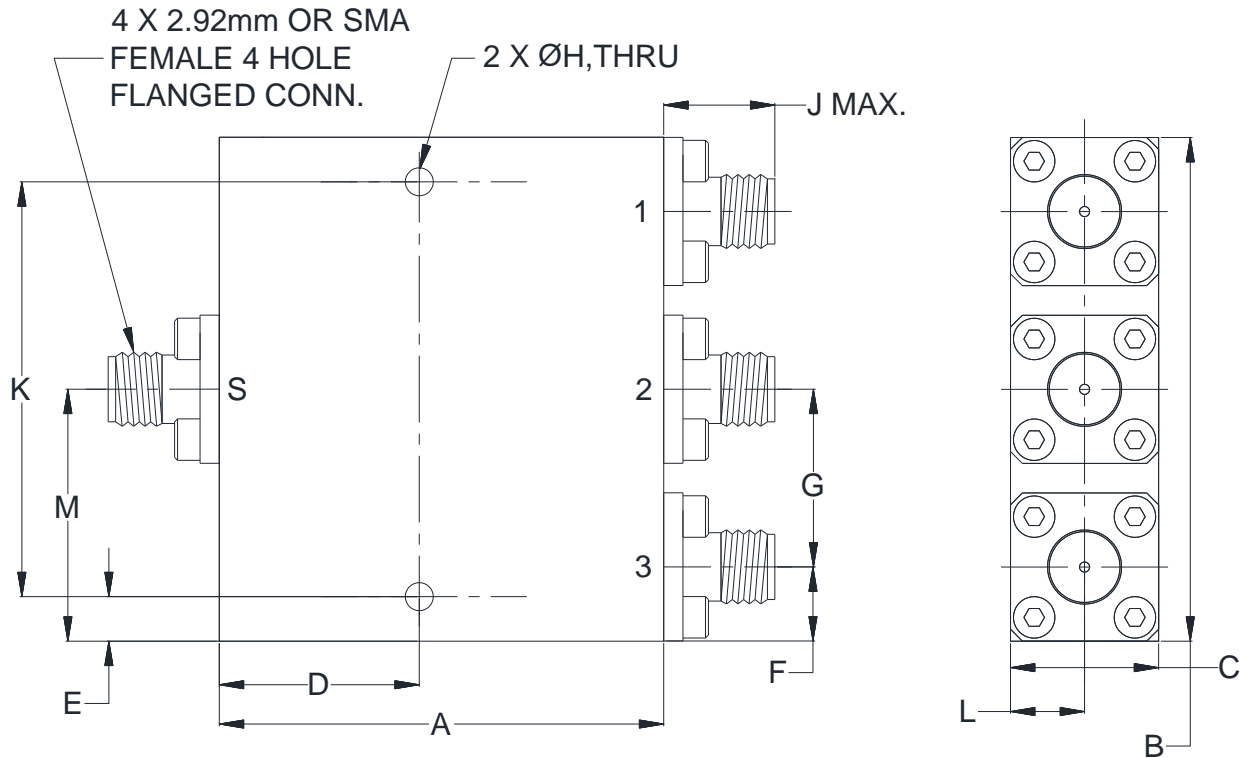

CASE#	A	B	C	D	E	F	G	H	J	K	L	M
UU2412-2	1.50 (38.10)	1.70 (43.18)	.50 (12.70)	.67 (17.14)	.150 (3.82)	.25 (6.35)	.60 (15.23)	0.094 (2.40)	.43 (11.0)	1.400 (35.56)	.25 (6.35)	0.85 (21.60)

CASE#	WT. GRAMS
UU2412-2	80

Dimensions are in inches (mm). Tolerances: 2 Pl.  $\pm .03$ ; 3 Pl.  $\pm .015$

### Notes:

1. Case material: Aluminum alloy.
2. Case finish: Painting Color: Blue.
3. Refer to the individual model data sheet for the type of connectors available.

**Mini-Circuits®**  
ISO 9001 ISO 14001 CERTIFIED

ALL NEW  
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS