


### Outline Dimensions

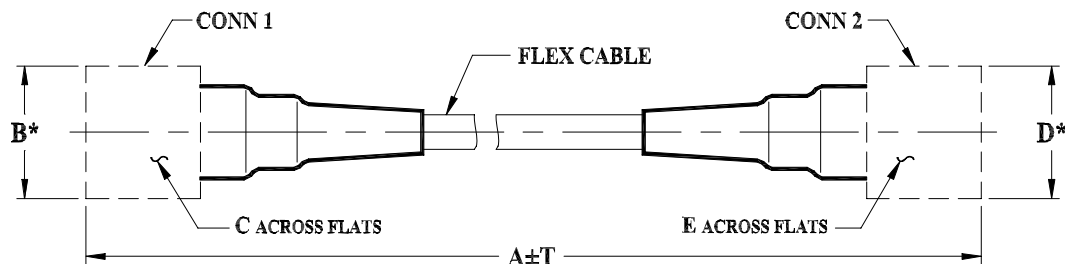

\* OVERALL CONNECTOR OR CABLE & BOOT DIMENSION  
(CONNECTOR SHAPE MAY VARY)

GM1106 SERIES

N MALE (CONN-1)

N MALE (CONN-2)

CASE STYLE #	A		B	C	D	E	T		WEIGHT GRAMS
	FEET	METERS					FEET	METERS	
GM1106-1	1	.30	.88 (22.35)	.812 (20.62)	.88 (22.35)	.812 (20.62)	.06	.02	117
GM1106-1.5	1.5	.46					.06	.02	127
GM1106-1.64	1.64	.50					.06	.02	129
GM1106-2	2	.61					.06	.02	137
GM1106-3	3	.91					.09	.03	156
GM1106-3.3	3.3	1.01					.10	.03	162
GM1106-4	4	1.22					.12	.04	176
GM1106-4.92	4.92	1.50					.15	.05	193
GM1106-5	5	1.52					.15	.05	195
GM1106-6	6	1.83					.18	.05	215
GM1106-6.56	6.56	2.00					.20	.06	225
GM1106-7.5	7.5	2.29					.23	.07	244
GM1106-9	9	2.74					.27	.08	273
GM1106-9.84	9.84	3.00					.30	.09	289
GM1106-10	10	3.05					.30	.09	293
GM1106-12	12	3.66					.36	.11	332
GM1106-13.12	13.12	4.00					.39	.12	353
GM1106-15	15	4.57					.45	.14	390
GM1106-20	20	6.10					.60	.18	488
GM1106-25	25	7.62					.75	.23	585
GM1106-30	30	9.14	.90	.27	683				
GM1106-50	50	15.24	1.50	.46	1073				

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

**Note:**

1. Flexible Coaxial Cable.