


Outline Dimensions

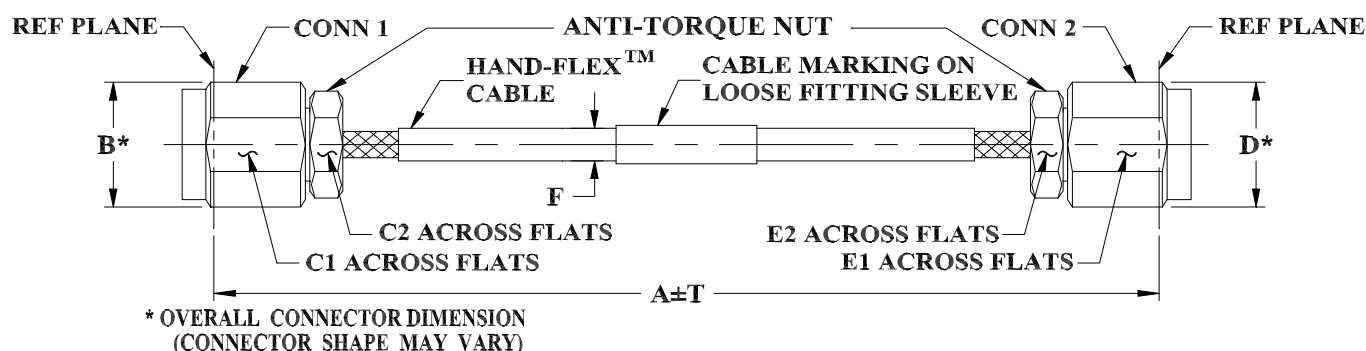

KQ1506 SERIES
SMA MALE (CONN-1)
SMA MALE (CONN-2)

| CASE STYLE # | A | | B | C1 | C2 | D | E1 | E2 | F | | T | | WEIGHT GRAMS |
|--------------|-------|--------|--------|--------|--------|--------|--------|--------|-------------|-------------|------|------|--------------|
| | INCH | MM | | | | | | | 141U-ASM+ | 141-ASM+ | INCH | MM | |
| KQ1506-2 | 2.00 | 50.80 | | | | | | | | | .05 | 1.27 | 6.89 |
| KQ1506-3 | 3.00 | 76.20 | | | | | | | | | .05 | 1.27 | 8.03 |
| KQ1506-4 | 4.00 | 101.60 | | | | | | | | | .05 | 1.27 | 9.17 |
| KQ1506-5 | 5.00 | 127.00 | | | | | | | | | .05 | 1.27 | 10.32 |
| KQ1506-6 | 6.00 | 152.40 | | | | | | | | | .05 | 1.27 | 11.46 |
| KQ1506-7 | 7.00 | 177.80 | | | | | | | | | .10 | 2.54 | 12.60 |
| KQ1506-8 | 8.00 | 203.20 | | | | | | | | | .10 | 2.54 | 13.74 |
| KQ1506-9 | 9.00 | 228.60 | | | | | | | | | .10 | 2.54 | 14.89 |
| KQ1506-10 | 10.00 | 254.00 | | | | | | | | | .10 | 2.54 | 16.03 |
| KQ1506-11 | 11.00 | 279.40 | | | | | | | | | .10 | 2.54 | 17.17 |
| KQ1506-12 | 12.00 | 304.80 | .36 | .315 | .250 | .36 | .315 | .250 | .141±.003 | .163±.004 | .10 | 2.54 | 18.32 |
| KQ1506-13 | 13.00 | 330.20 | (9.14) | (8.00) | (6.35) | (9.14) | (8.00) | (6.35) | (3.58±0.07) | (4.14±0.10) | .15 | 3.81 | 19.46 |
| KQ1506-14 | 14.00 | 355.60 | | | | | | | | | .15 | 3.81 | 20.60 |
| KQ1506-15 | 15.00 | 381.00 | | | | | | | | | .15 | 3.81 | 21.75 |
| KQ1506-16 | 16.00 | 406.40 | | | | | | | | | .15 | 3.81 | 22.89 |
| KQ1506-17 | 17.00 | 431.80 | | | | | | | | | .15 | 3.81 | 24.03 |
| KQ1506-18 | 18.00 | 457.20 | | | | | | | | | .15 | 3.81 | 25.17 |
| KQ1506-19 | 19.00 | 482.60 | | | | | | | | | .15 | 3.81 | 26.32 |
| KQ1506-19.7 | 19.69 | 500.00 | | | | | | | | | .15 | 3.81 | 27.12 |
| KQ1506-20 | 20.00 | 508.00 | | | | | | | | | .15 | 3.81 | 27.45 |
| KQ1506-22 | 22.00 | 558.80 | | | | | | | | | .15 | 3.81 | 29.75 |
| KQ1506-24 | 24.00 | 609.60 | | | | | | | | | .15 | 3.81 | 32.03 |

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

1. 141 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified

Case Style

KQ

KQ1506

Outline Dimensions

KQ1506 SERIES
SMA MALE (CONN-1)
SMA MALE (CONN-2)

| CASE STYLE # | A | | B | C1 | C2 | D | E1 | E2 | F | | T | | WEIGHT GRAMS | | | | | | | | | |
|-----------------|-------|---------|---------------|----------------|----------------|---------------|----------------|----------------|--|--|------|-------|-----------------|--|--|--|--|--|--|--|--|--|
| | INCH | MM | | | | | | | 141U-ASM+ | 141-ASM+ | INCH | MM | | | | | | | | | | |
| KQ1506-26 | 26.00 | 660.40 | .36 (9.14) | .315 (8.00) | .250 (6.35) | .36 (9.14) | .315 (8.00) | .250 (6.35) | .141 ∇ .003 (3.58 ∇ 0.07) | .163 ∇ .004 (4.14 ∇ 0.10) | .20 | 5.08 | 34.32 | | | | | | | | | |
| KQ1506-30 | 30.00 | 762.00 | | | | | | | | | .20 | 5.08 | 38.89 | | | | | | | | | |
| KQ1506-32 | 32.00 | 812.80 | | | | | | | | | .20 | 5.08 | 41.18 | | | | | | | | | |
| KQ1506-36 | 36.00 | 914.40 | | | | | | | | | .30 | 7.62 | 45.75 | | | | | | | | | |
| KQ1506-39.4 | 39.37 | 1000.00 | | | | | | | | | .30 | 7.62 | 49.63 | | | | | | | | | |
| KQ1506-40 | 40.00 | 1016.00 | | | | | | | | | .30 | 7.62 | 50.32 | | | | | | | | | |
| KQ1506-48 | 48.00 | 1219.20 | | | | | | | | | .40 | 10.16 | 61.75 | | | | | | | | | |
| KQ1506-50 | 50.0 | 1270.00 | | | | | | | | | .40 | 10.16 | 72.15 | | | | | | | | | |
| KQ1506-59.1 | 59.06 | 1500.00 | | | | | | | | | .40 | 10.16 | 73.18 | | | | | | | | | |
| KQ1506-60 | 60.00 | 1524.00 | | | | | | | | | .40 | 10.16 | 73.18 | | | | | | | | | |
| KQ1506-72 | 72.00 | 1828.80 | | | | | | | | | .40 | 10.16 | 86.90 | | | | | | | | | |
| KQ1506-78.7 | 78.74 | 2000.00 | | | | | | | | | .40 | 10.16 | 94.55 | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | | | | | | | | | |

Unless otherwise specified dimensions are in inches (mm).
Tolerances: 2Pl. \pm .03; 3Pl. \pm .015



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified