


Outline Dimensions

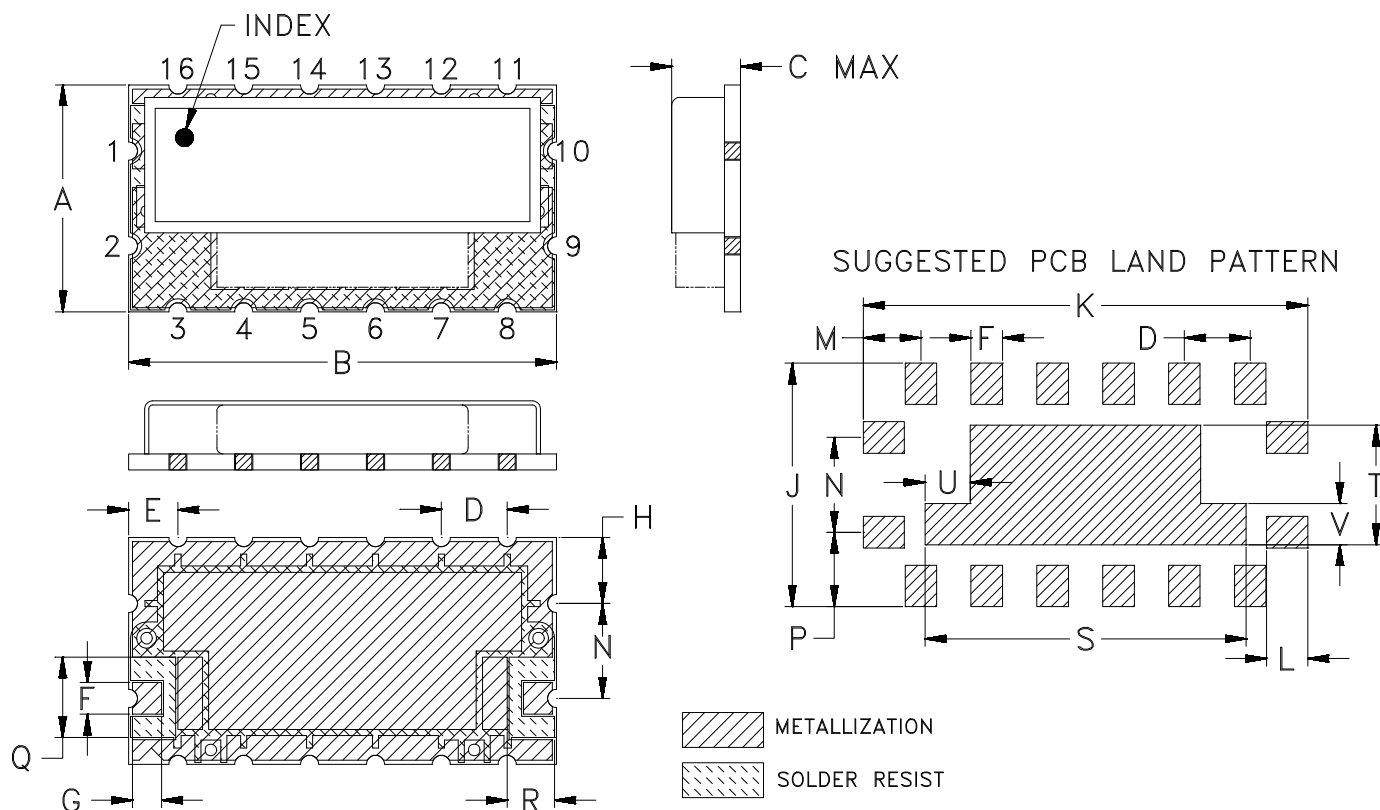

CASE#	A	B	C	D	E	F	G	H	J	K	L	M
KU1513	.550 (13.97)	1.040 (26.24)	.185 (4.70)	.160 (4.06)	.120 (3.05)	.077 (1.96)	.070 (1.78)	.160 (4.06)	.590 (14.99)	1.080 (27.43)	.100 (2.54)	.140 (3.56)

CASE#	N	P	Q	R	S	T	U	V	WT, GRAMS
KU1513	.230 (5.84)	.180 (4.57)	.195 (4.95)	.115 (2.92)	.780 (19.81)	.290 (7.36)	.110 (2.79)	.100 (2.54)	2.6

Dimensions are in inches (mm). Tolerances: 2PL. ±.03; 3PL. ±.015

Notes:

- Case material: Nickel-Silver alloy.
- Base: Printed wiring laminate.
- Termination finish:
For RoHS Case Styles: 2-5 μ inch (.05-.13 microns) Gold over 120-240 μ inch (3.05-6.10 microns) Nickel plate.
All models, (+) suffix.

Mini-Circuits®

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified