


Outline Dimensions

ND1919

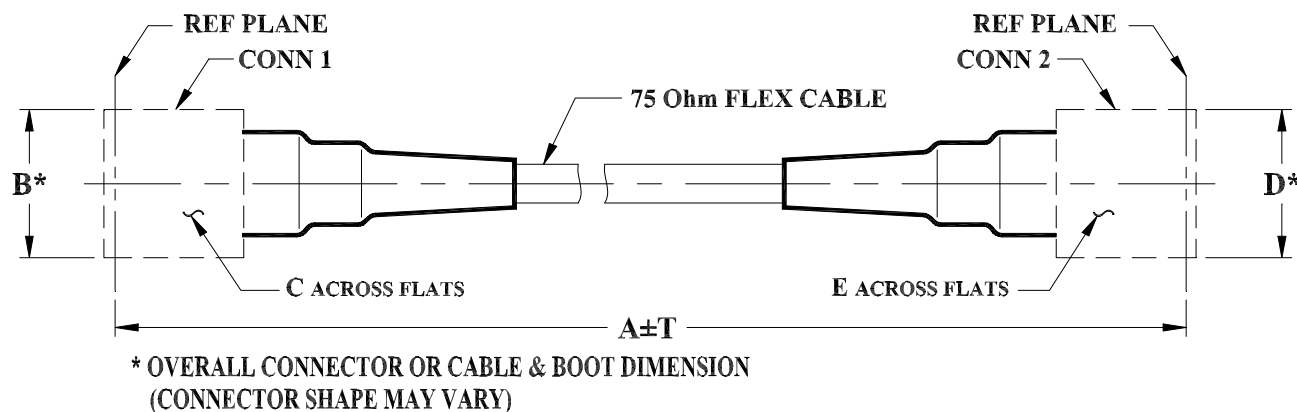

ND1919 SERIES

F MALE 75 Ohm (CONN-1)

F MALE 75 Ohm (CONN-2)

CASE STYLE #	A		B	C	D	E	T		WEIGHT GRAMS
	FEET	METERS					FEET	METERS	
ND1919-2	2.00	.61	.54 (13.72)	.500 (12.70)	.54 (13.72)	.500 (12.70)	.06	.02	91
ND1919-3	3.00	.91					.09	.03	110
ND1919-3.28	3.28	1.00					.10	.03	116
ND1919-6	6.00	1.83					.18	.05	168

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

- 75 Ohm Flexible Coaxial Cable.