


Case Style

UM

Outline Dimensions

UM3060

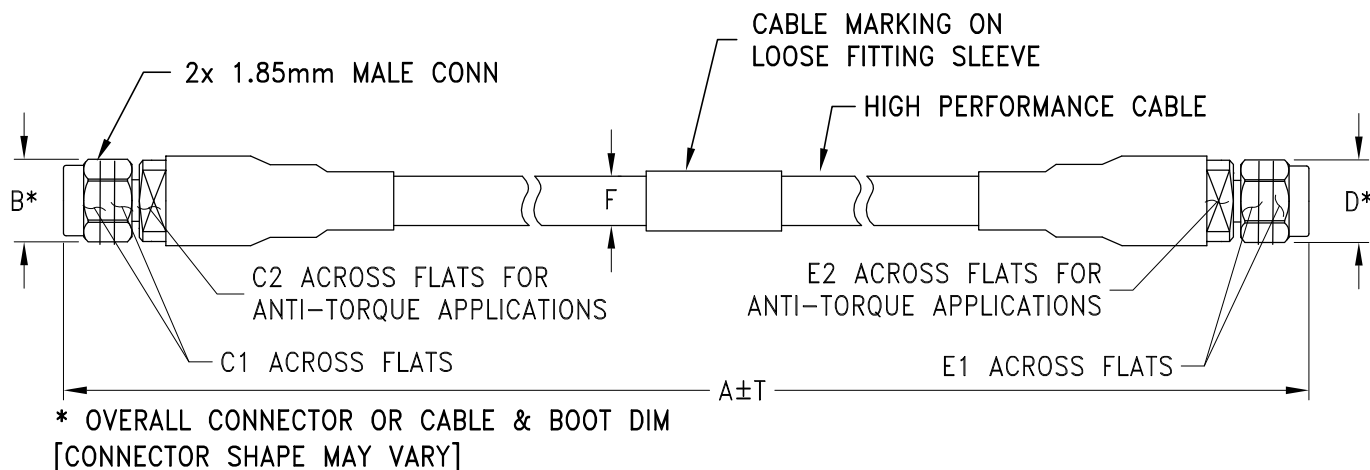

UM3060 SERIES 1.85 MM MALE (CONN)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F	T		WT. (GRAMS)
	FEET	M								INCH	MM	
UM3060-1.64	1.64	0.50								.08	2.0	34.0
UM3060-2.00	2.00	0.61	0.36	.315	.256	.36	.315	.256	.100	.08	2.0	35.0
UM3060-3.00	3.00	0.91	[9.14]	[8.00]	[6.50]	[9.14]	[8.00]	[6.50]	[2.54]	.08	2.0	40.0
UM3060-3.28	3.28	1.00								.08	2.0	42.0

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2 Pl. ±.03; 3 Pl. ±.015

Note:

1. E67 Flexible Coaxial Cable.
2. "A" Represents Length of Cable.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS