
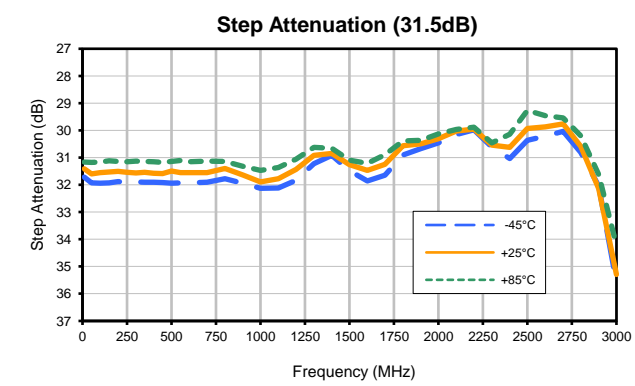
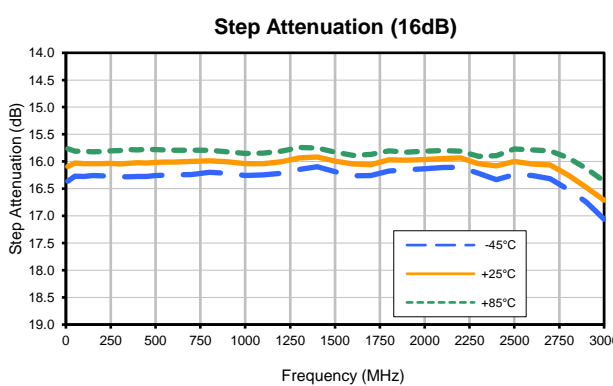
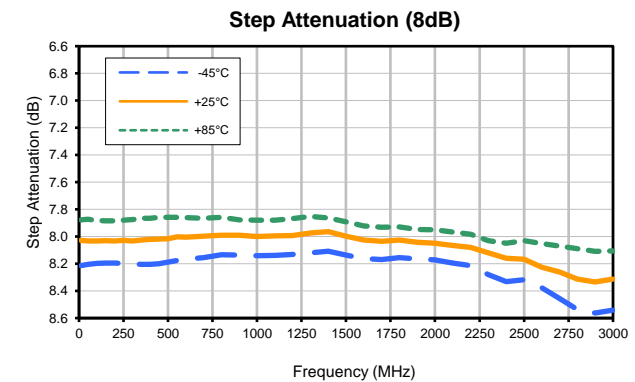
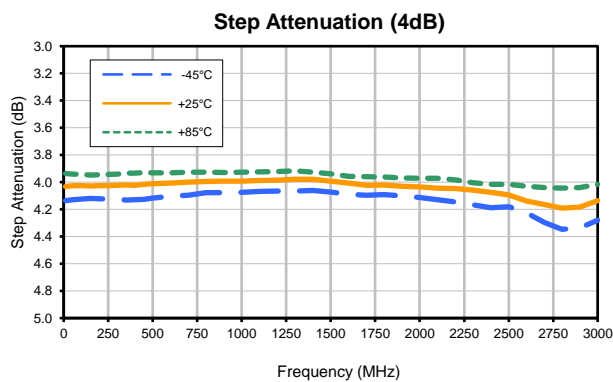
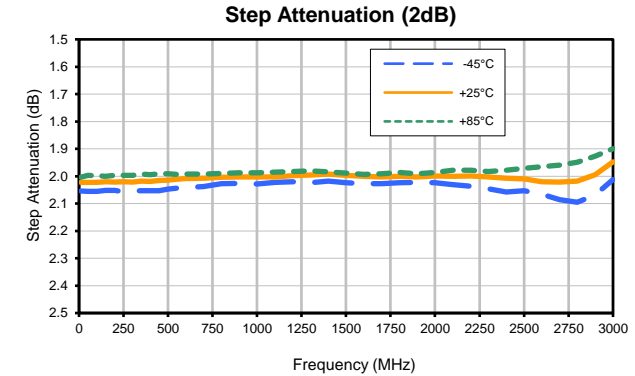
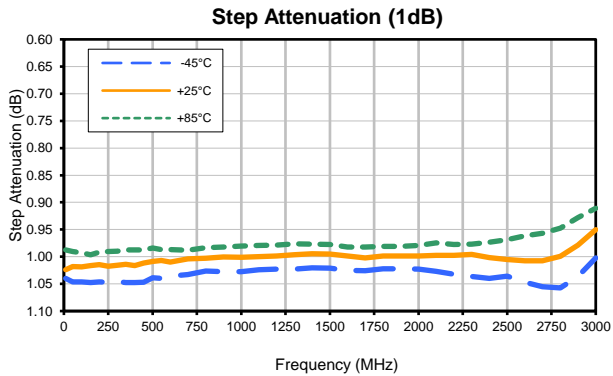
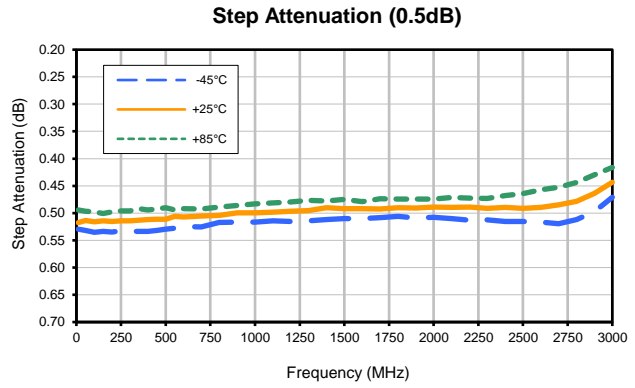


# Digital Step Attenuator

## Typical Performance Curves

# DAT-31575A-PP+

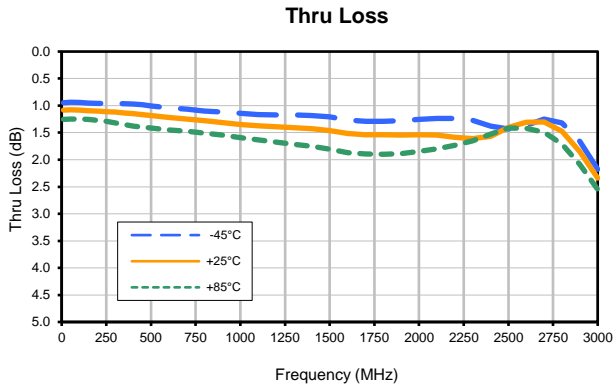


# Digital Step Attenuator


## Typical Performance Curves

# DAT-31575A-PP+


Input Return Loss (0dB)

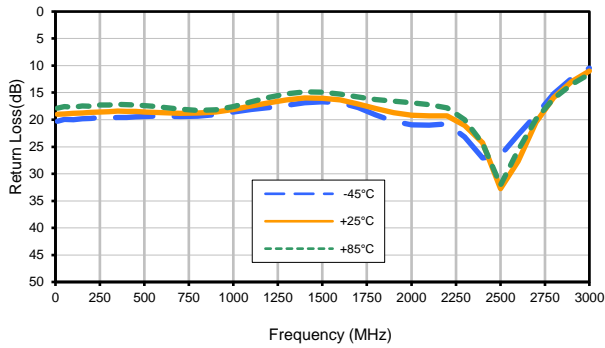


Input Return Loss (0.5dB)

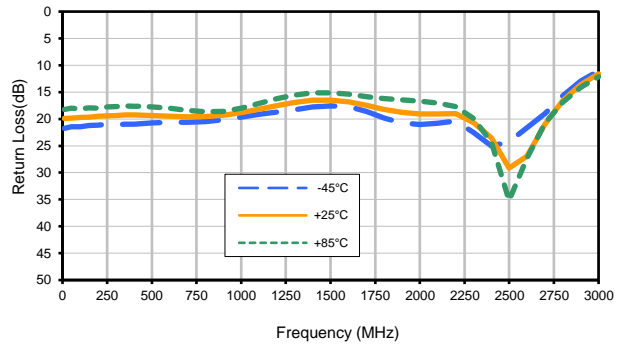


Input Return Loss (1dB)

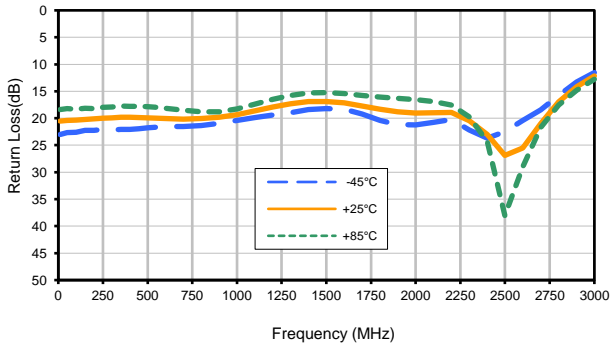


Input Return Loss (2dB)

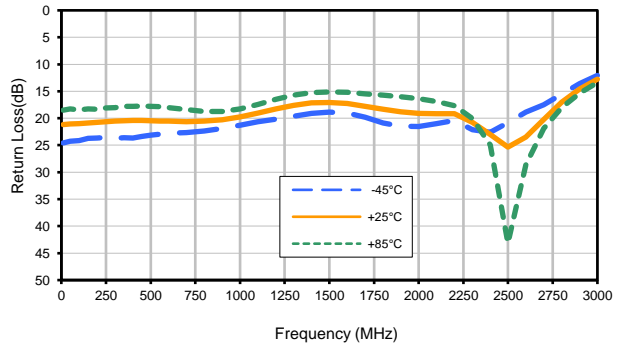


Input Return Loss (4dB)

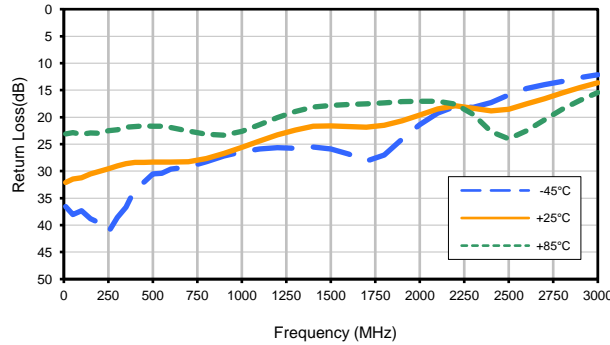


Input Return Loss (8dB)

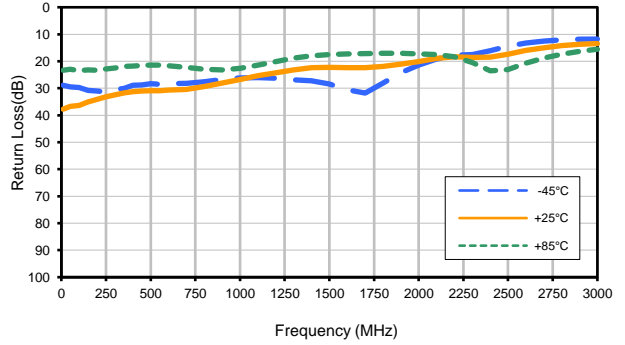

Input Return Loss (16dB)

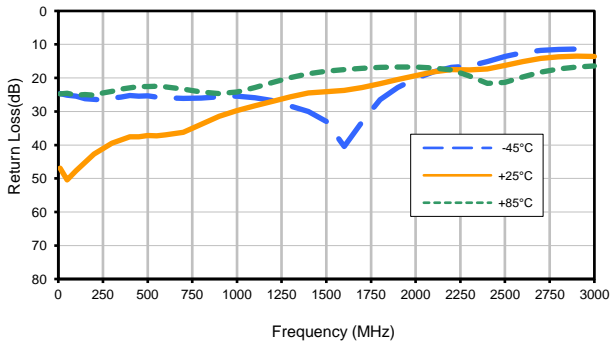

Input Return Loss (31.5dB)

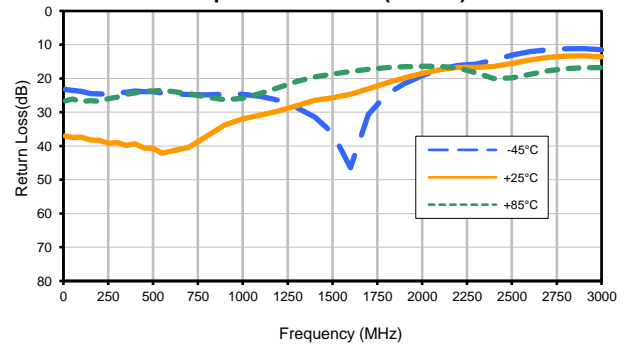


# Digital Step Attenuator


## Typical Performance Curves

# DAT-31575A-PP+


Output Return Loss (0dB)

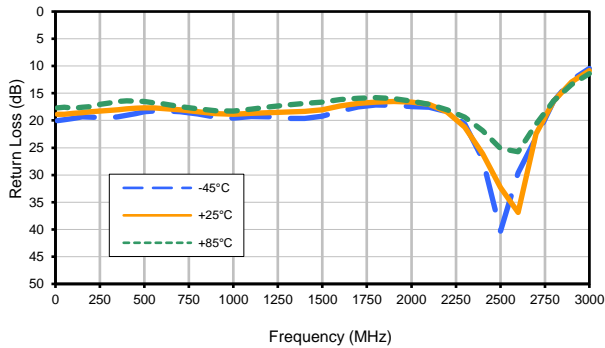


Output Return Loss (0.5dB)

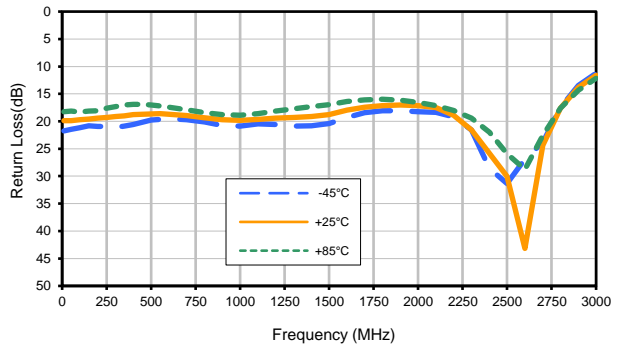


Output Return Loss (1dB)

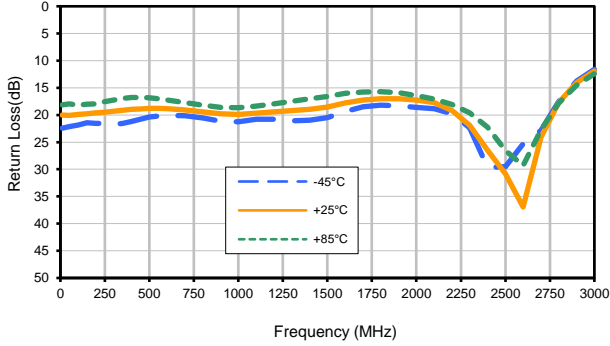


Output Return Loss (2dB)

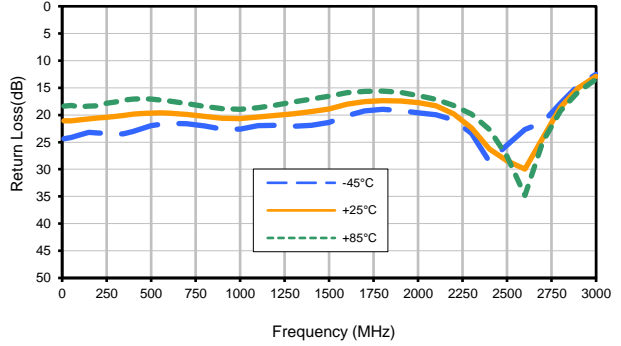


Output Return Loss (4dB)

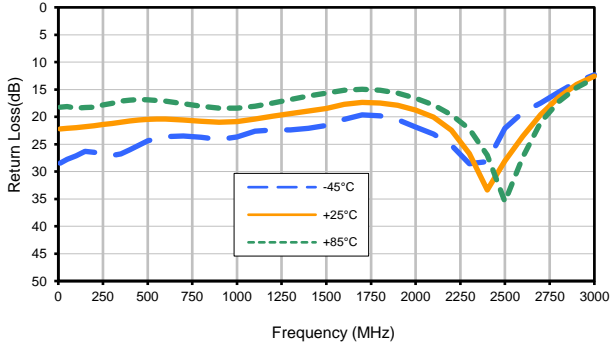

Output Return Loss (8dB)

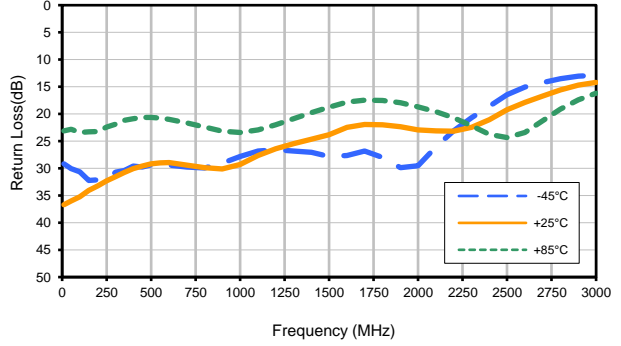

Output Return Loss (16dB)

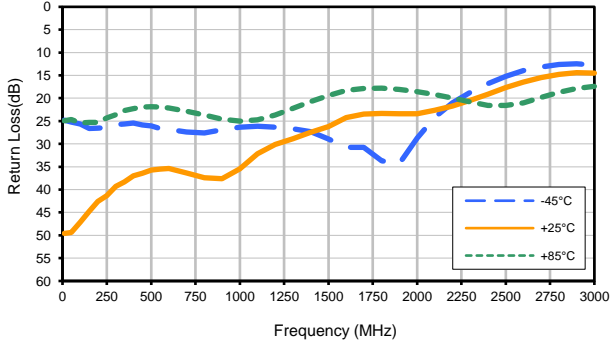

Output Return Loss (31.5dB)

