

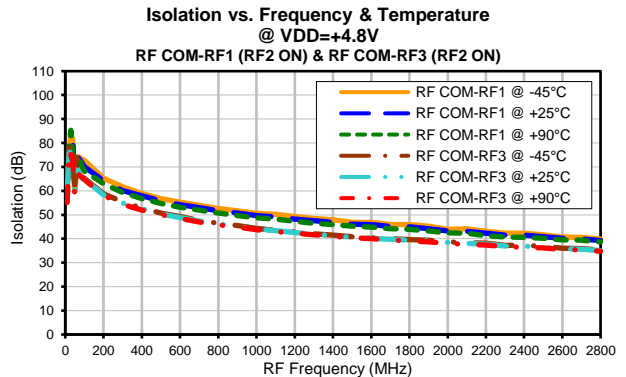
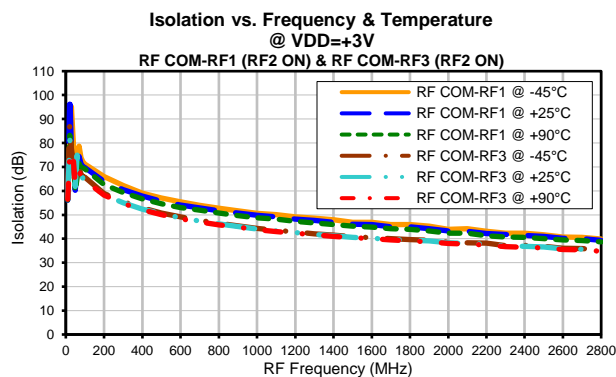
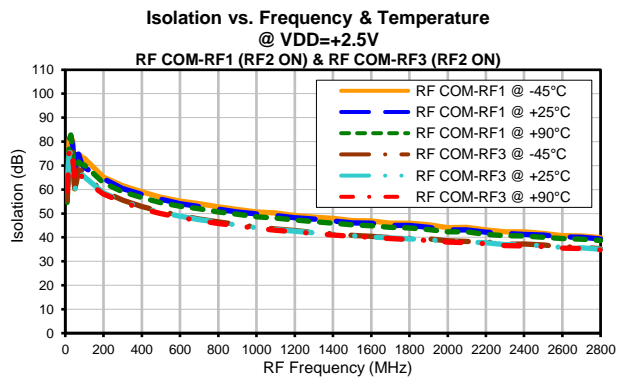
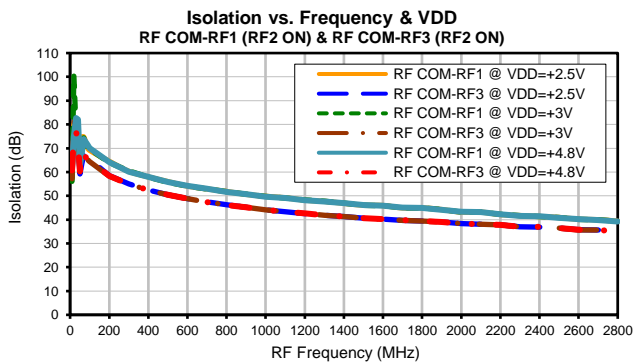
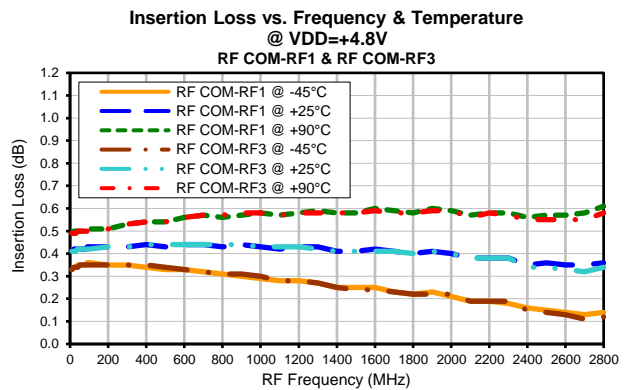
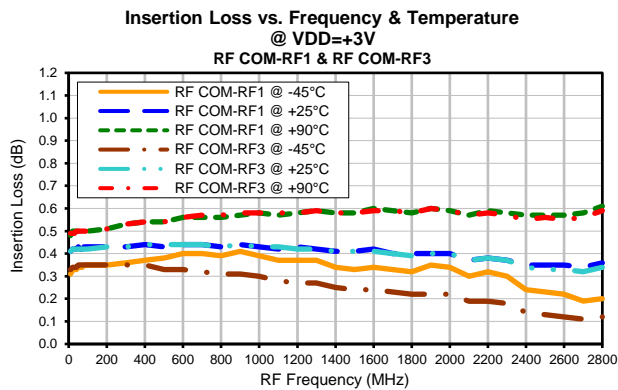
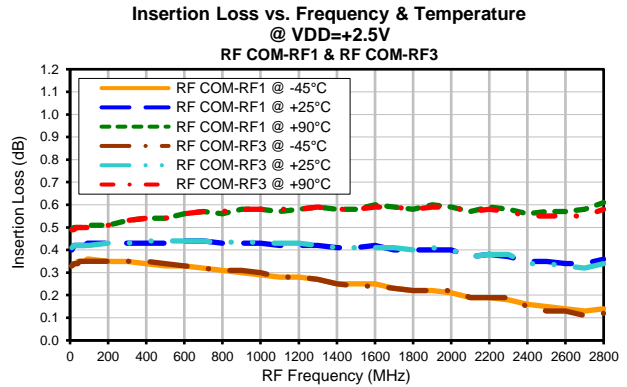
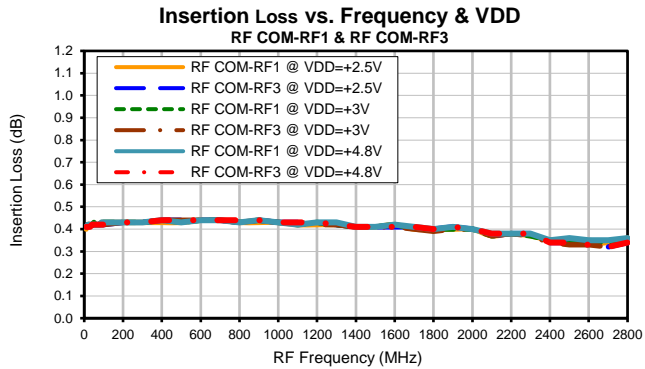
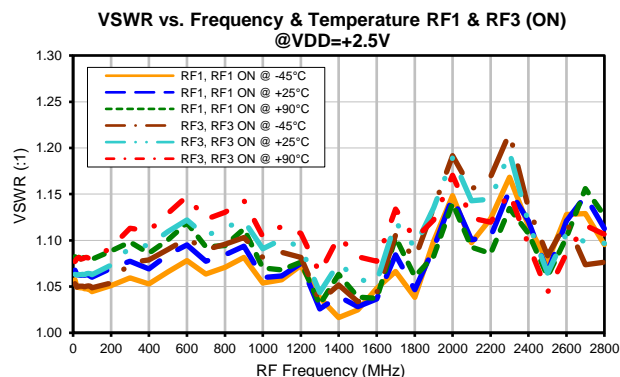
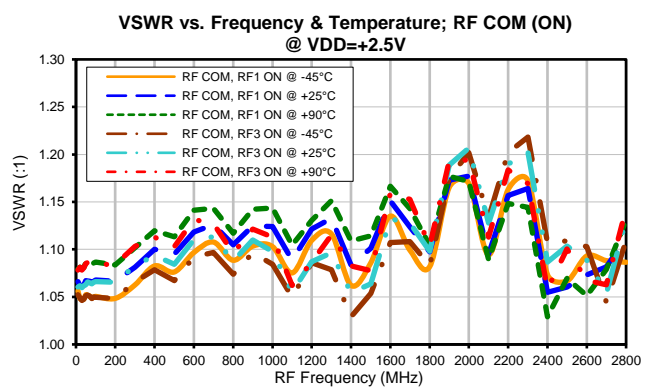
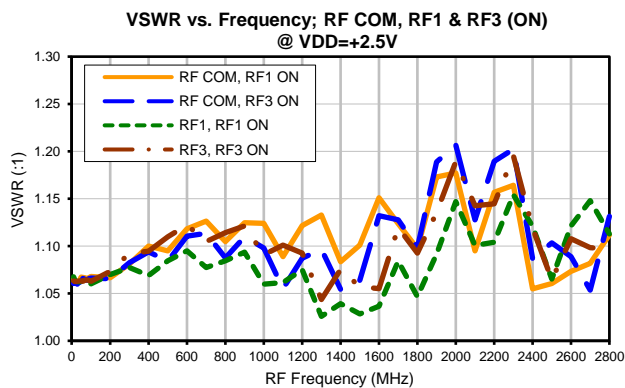
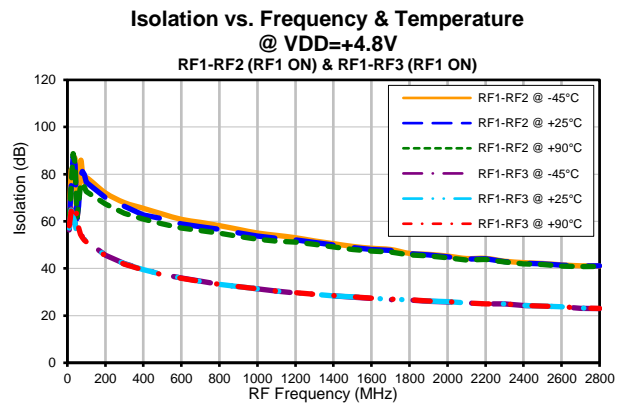
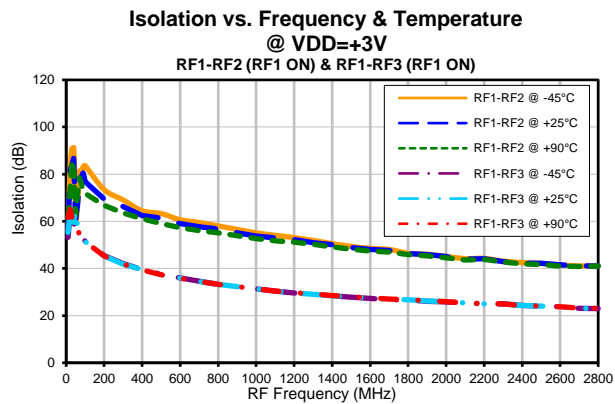










Typical Performance Curves

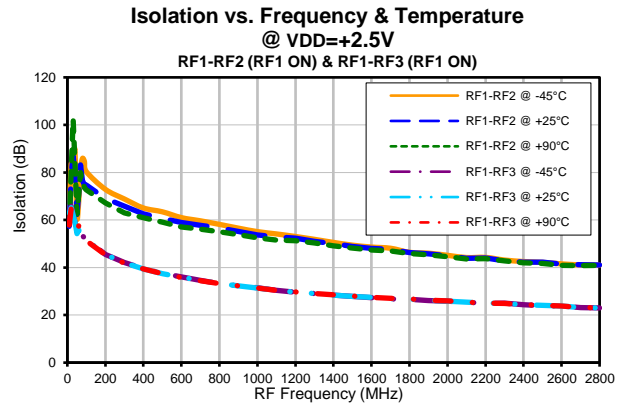

Typical Performance Curves

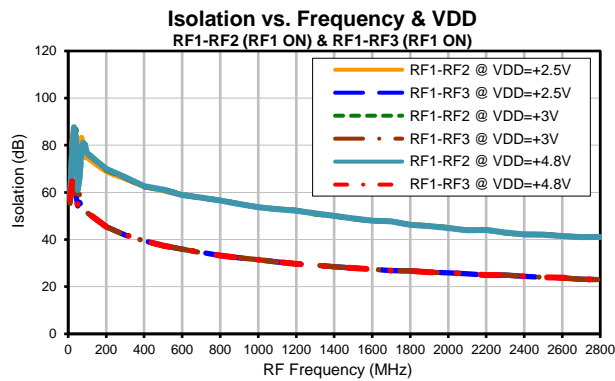


Typical Performance Curves

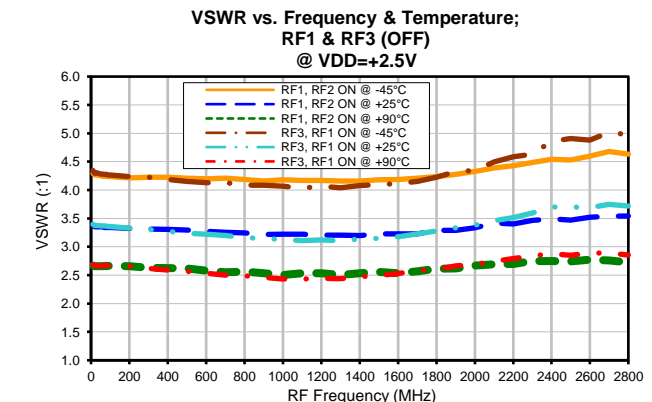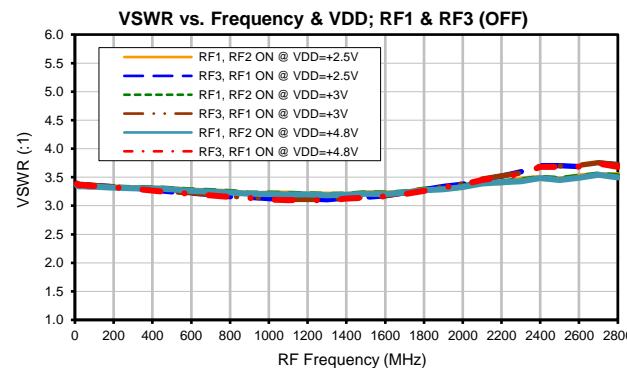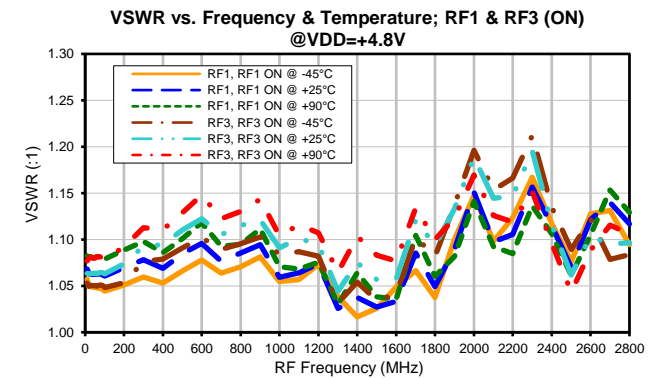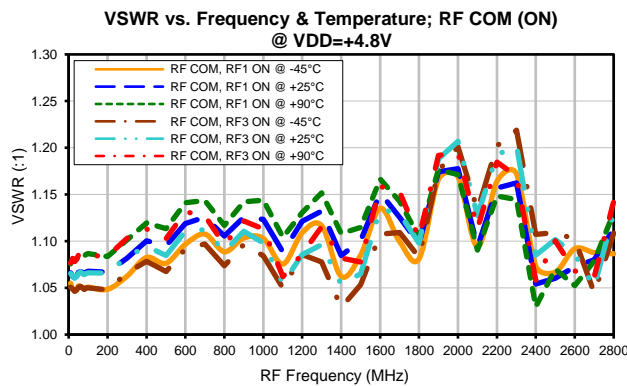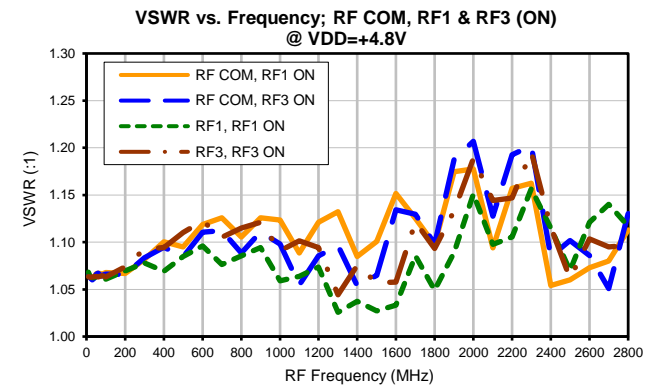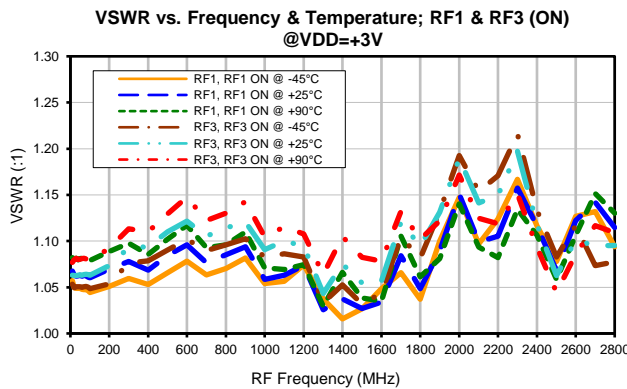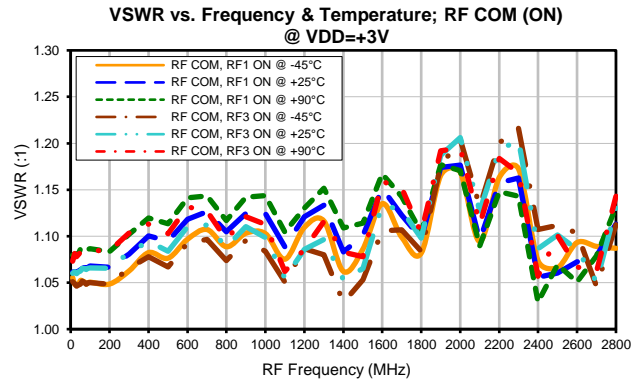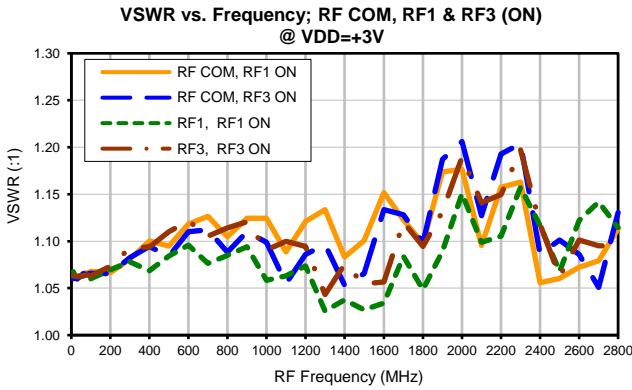


Typical Performance Curves


VSWR vs. Frequency & Temperature;
RF1 & RF3 (OFF)
@ VDD=+3V

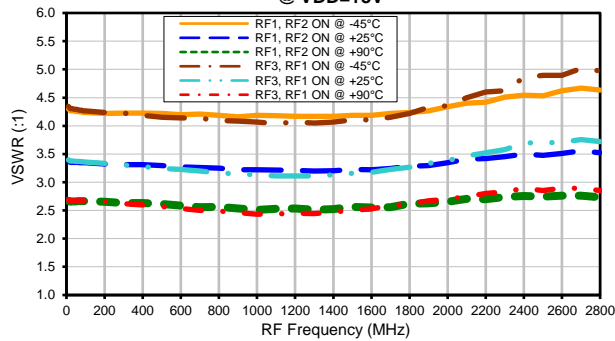

VSWR vs. Frequency & Temperature;
RF1 & RF3 (OFF)
@ VDD=+4.8V

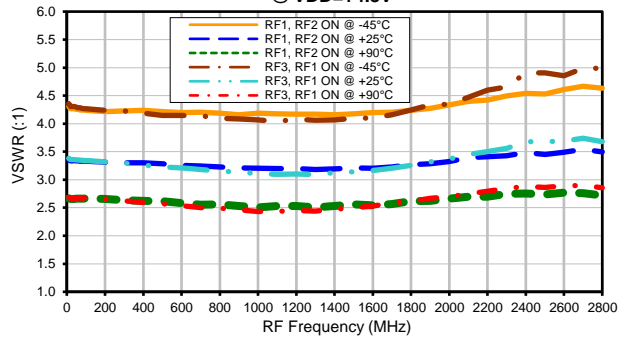

Input IP3 vs. Frequency

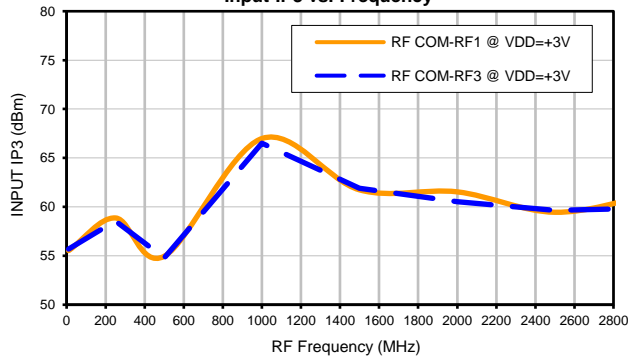

Compression vs. Frequency
@ Fixed power (Pin=34.5 dBm)

