


Outline Dimensions

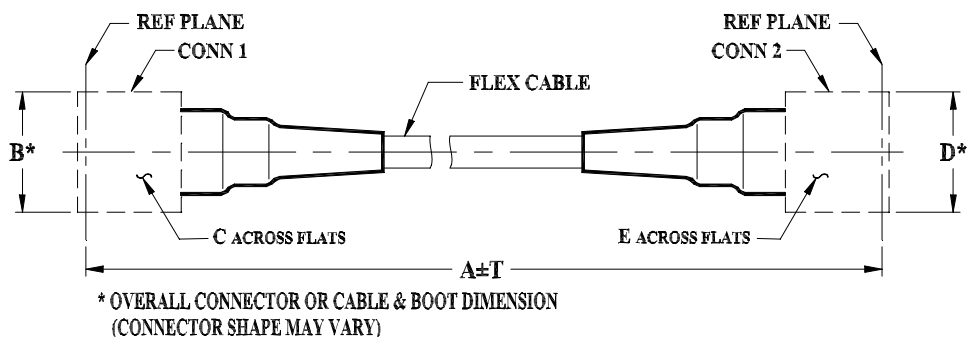

GM1106 SERIES
N MALE (CONN-1)
N MALE (CONN-2)

CASE STYLE #	A		B	C	D	E	T		WEIGHT GRAMS
	FEET	METERS					FEET	METERS	
GM1106-1	1.00	.30	.88 (22.35)	.750 (19.05)	.88 (22.35)	.750 (19.05)	.06	.02	117
GM1106-1.5	1.50	.46					.06	.02	127
GM1106-1.64	1.64	.50					.06	.02	129
GM1106-2	2.00	.61					.06	.02	137
GM1106-3	3.00	.91					.09	.03	156
GM1106-3.28	3.28	1.00					.10	.03	161
GM1106-4	4.00	1.22					.12	.04	176
GM1106-4.92	4.92	1.50					.15	.05	193
GM1106-5	5.00	1.52					.15	.05	195
GM1106-6	6.00	1.83					.18	.05	215
GM1106-6.56	6.56	2.00					.20	.06	225
GM1106-7	7.00	2.13					.21	.06	221
GM1106-7.5	7.50	2.29					.23	.07	244
GM1106-8	8.00	2.44					.24	.07	240
GM1106-9	9.00	2.74					.27	.08	273
GM1106-9.84	9.84	3.00					.30	.09	289
GM1106-10	10.00	3.05					.30	.09	293
GM1106-12	12.00	3.66					.36	.11	332
GM1106-13.1	13.12	4.00					.39	.12	353
GM1106-15	15.00	4.57					.45	.14	390
GM1106-16.4	16.40	5.00	.49	.15	417				
GM1106-20	20.00	6.10	.60	.18	488				
GM1106-25	25.00	7.62	.75	.23	585				
GM1106-30	30.00	9.14	.90	.27	683				
GM1106-50	50.00	15.24	1.50	.46	1073				
GM1106-131	131.23	40.00	3.94	1.20	2656				

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ±.03; 3Pl. ±.015

Note:

1. Flexible Coaxial Cable.



Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661