

Non-Catalog Model

RF Transformer

Impedance Ratio : 1.5

TMO1.5-1

Important Note

This is a non-catalog model and can be manufactured on specific request.
Pricing and delivery information can be supplied upon request.



Please click "Back", and then click "Contact Us" for Applications support.

CASE STYLE : A11


ELECTRICAL SPECIFICATIONS 50Ω @ +25°C					
Parameter		Min.	Typ.	Max.	Units
Frequency		0.1		300	MHz
Insertion Loss *	3 dB Bandwidth		0.1 - 300		MHz
	2 dB Bandwidth		0.2 - 150		MHz
	1 dB Bandwidth		0.5 - 80		MHz

Note:

* Insertion Loss is referenced to mid-band loss, 0.37dB typ.

MAXIMUM RATINGS	
Operating Temperature	-55°C to 100°C
Storage Temperature	-55°C to 100°C
RF Power	0.25 W
DC Current	30 mA

Configuration : C

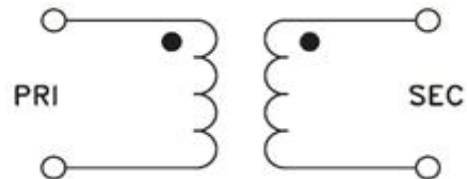

PIN CONNECTIONS	
PRIMARY DOT	1
PRIMARY	5
SECONDARY DOT	2
SECONDARY	6
CASE GND	7,8
NOT USED	3,4