


### Outline Dimensions

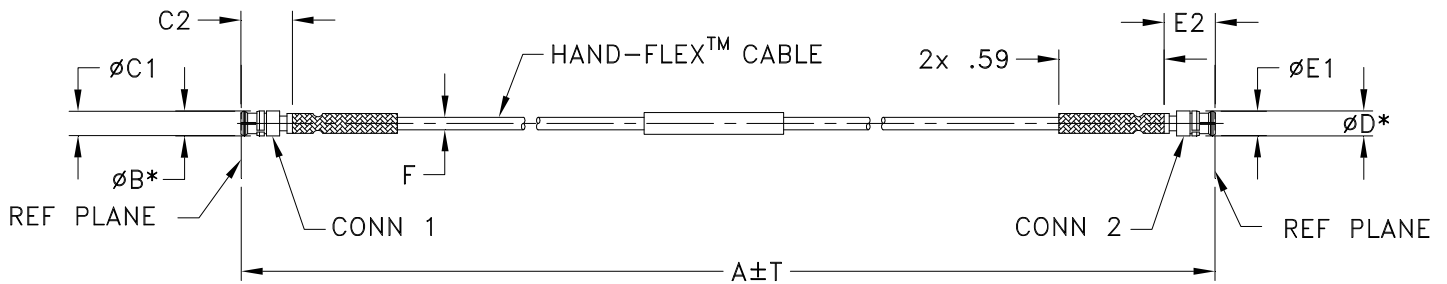

\* OVERALL CONNECTOR DIMENSION [CONNECTOR SHAPE MAY VARY]

**BZ2551 SERIES**  
**SMP FEMALE (CONN-1)**  
**SMP FEMALE (CONN-2)**

| CASE STYLE # | A     |        | B             | C1             | C2             | D             | E1             | E2             | F                      |                        | G  | H  | T    |      | WEIGHT GRAMS |
|--------------|-------|--------|---------------|----------------|----------------|---------------|----------------|----------------|------------------------|------------------------|----|----|------|------|--------------|
|              | INCH  | MM     |               |                |                |               |                |                | 047U-ASMP+             | 047-ASMP+              |    |    | INCH | MM   |              |
| BZ2551-3     | 3.00  | 76.20  | .14<br>(3.50) | .135<br>(3.43) | .287<br>(7.35) | .14<br>(3.50) | .135<br>(3.43) | .289<br>(7.35) | .048 MAX<br>(1.22 MAX) | .069 MAX<br>(1.75 MAX) | -- | -- | .05  | 1.27 | 1.37         |
| BZ2551-4     | 4.00  | 101.60 |               |                |                |               |                |                |                        |                        | -- | -- | .05  | 1.27 | 1.66         |
| BZ2551-5     | 5.00  | 127.00 |               |                |                |               |                |                |                        |                        | -- | -- | .05  | 1.27 | 1.95         |
| BZ2551-6     | 6.00  | 152.40 |               |                |                |               |                |                |                        |                        | -- | -- | .05  | 1.27 | 2.24         |
| BZ2551-7     | 7.00  | 177.80 |               |                |                |               |                |                |                        |                        | -- | -- | .10  | 2.54 | 2.53         |
| BZ2551-8     | 8.00  | 203.20 |               |                |                |               |                |                |                        |                        | -- | -- | .10  | 2.54 | 2.82         |
| BZ2551-10    | 10.00 | 254.00 |               |                |                |               |                |                |                        |                        | -- | -- | .10  | 2.54 | 3.40         |
| BZ2551-12    | 12.00 | 304.80 |               |                |                |               |                |                |                        |                        | -- | -- | .10  | 2.54 | 3.98         |

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

**Note:**

1. 047 Hand-Flex™ Coaxial Cable.
2. "A" represents length of cable.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified