


Outline Dimensions

FP914-PM

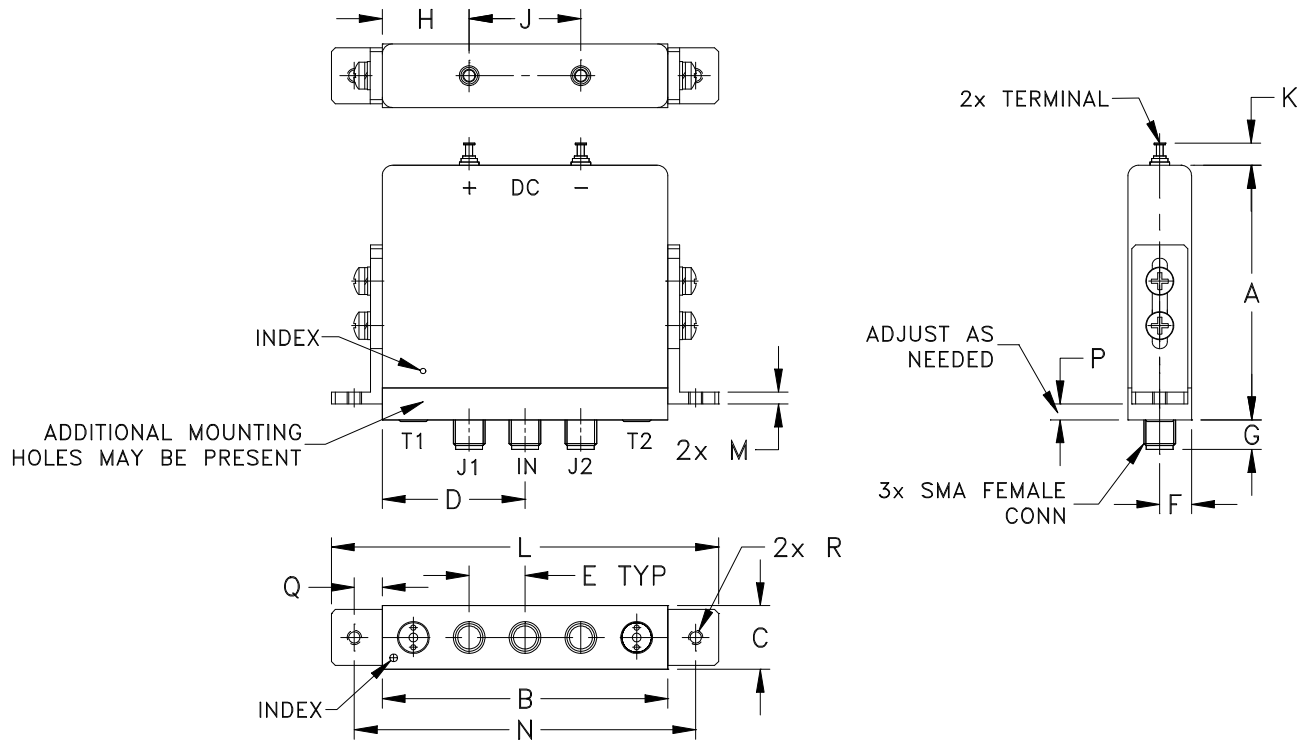

CASE #.	A	B	C	D	E	F	G	H	J	K	L	M	N
FP914-PM	2.00 (50.80)	2.25 (57.15)	.50 (12.70)	1.125 (28.58)	.440 (11.18)	.25 (6.35)	.24 (6.10)	.755 (19.18)	.740 (18.80)	.19 (4.83)	3.05 (7.75)	.094 (2.38)	2.69 (68.33)

CASE #.	P	Q	R	WT, GRAM
FP914-PM	0 MIN/.25 MAX (0 MIN/6.35 MAX)	.22 (5.58)	#4-40 (-)	102

Dimensions are in inches (mm). Tolerances: 2Pl. $\pm .03$; 3Pl. $\pm .015$

Note:

- Case material: Copper-Nickel alloy.

Mini-Circuits[®]

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified