


### Outline Dimensions

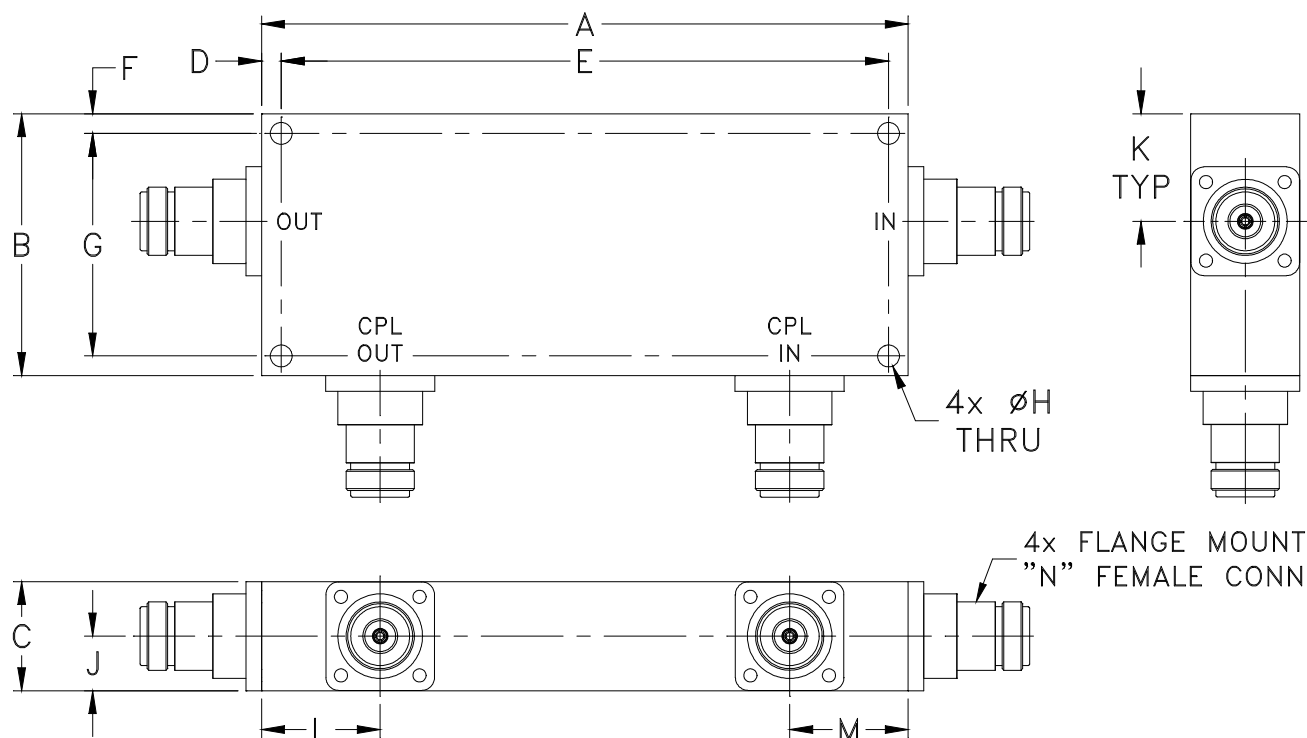

| CASE # | A                | B               | C               | D             | E                 | F             | G                | H              | J              | K              |
|--------|------------------|-----------------|-----------------|---------------|-------------------|---------------|------------------|----------------|----------------|----------------|
| HT1760 | 5.93<br>(150.62) | 2.40<br>(60.96) | 1.00<br>(25.40) | .18<br>(4.57) | 5.565<br>(141.35) | .18<br>(4.57) | 2.040<br>(51.82) | .200<br>(5.08) | .50<br>(12.70) | .99<br>(25.15) |

| CASE # | L               | M               | WT. GRAM |
|--------|-----------------|-----------------|----------|
| HT1760 | 1.09<br>(27.69) | 1.09<br>(27.69) | 700.0    |

Dimensions are in inches (mm). Tolerances: 2Pl.  $\pm .03$ ; 3Pl.  $\pm .015$

### Notes:

- Case material: Aluminum alloy.
- Case finish:  
For RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based.