


# Case Style

# KP

## Outline Dimensions

## KP1505

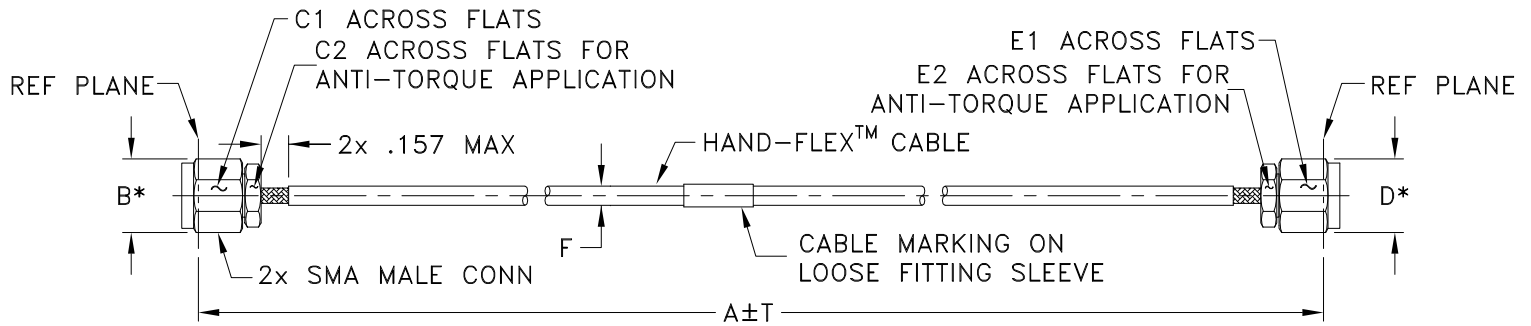

\* OVERALL CONNECTOR DIMENSION  
[CONNECTOR SHAPE MAY VARY]

### KP1505 SERIES

- SMA MALE (CONN-1)
- SMA MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		T		WT. (GRAMS)
	INCH	MM							086U-ASM+ (UNJACKETED)	086-ASM+ (JACKETED)	INCH	MM	
KP1505-2	2.00	50.80									.05	1.27	6.11
KP1505-3	3.00	76.20									.05	1.27	6.57
KP1505-3.94	3.94	100.00									.05	1.27	7.00
KP1505-4	4.00	101.60									.05	1.27	7.03
KP1505-5	5.00	127.00									.05	1.27	7.49
KP1505-6	6.00	152.40									.05	1.27	7.94
KP1505-7	7.00	177.80									.10	2.54	8.40
KP1505-7.87	7.87	200.00									.10	2.54	8.80
KP1505-8	8.00	203.20									.10	2.54	8.86
KP1505-9	9.00	228.60									.10	2.54	9.31
KP1505-9.5	9.50	241.30									.10	2.54	9.54
KP1505-10	10.00	254.00	.36	.315	.250	.36	.315	.250	.091 MAX	.123 MAX	.10	2.54	9.77
KP1505-11	11.00	279.40	[9.14]	[8.00]	[6.35]	[9.14]	[8.00]	[6.35]	[2.31 MAX]	[3.12 MAX]	.10	2.54	10.23
KP1505-11.5	11.50	292.10									.10	2.54	10.46
KP1505-11.8	11.81	300.00									.10	2.54	10.59
KP1505-12	12.00	304.80									.10	2.54	10.68
KP1505-12.5	12.50	317.50									.15	3.81	10.91
KP1505-13	13.00	330.20									.15	3.81	11.14
KP1505-14	14.00	355.60									.15	3.81	11.60
KP1505-15	15.00	381.00									.15	3.81	12.06
KP1505-15.5	15.50	393.70									.15	3.81	12.28
KP1505-16	16.00	406.40									.15	3.81	12.51
KP1505-18	18.00	457.20									.15	3.81	13.43
KP1505-19.7	19.69	500.00									.15	3.81	14.20
KP1505-20	20.00	508.00									.15	3.81	14.34
KP1505-22	22.00	558.80									.15	3.81	15.25

Unless Otherwise Specified dimensions are in inches (mm),  
Tolerances: 2Pl.±.03; 3Pl.±.015

### Notes:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS

## Outline Dimensions

## KP1505

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		T		WT. (GRAMS)
	INCH	MM							086U-ASM+ (UNJACKETED)	086-ASM+ (JACKETED)	INCH	MM	
KP1505-24	24.00	609.60									.15	3.81	16.17
KP1505-26	26.00	660.40									.20	5.08	17.08
KP1505-27	27.00	685.80	.36	.315	.250	.36	.315	.250	.091 MAX	.123 MAX	.20	5.08	17.54
KP1505-30	30.00	762.00	[9.14]	[8.00]	[6.35]	[9.14]	[8.00]	[6.35]	[2.31 MAX]	[3.12 MAX]	.20	5.08	18.91
KP1505-36	36.00	914.40									.20	5.08	21.65
KP1505-48	48.00	1219.20									.30	7.62	27.14



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS