


Outline Dimensions

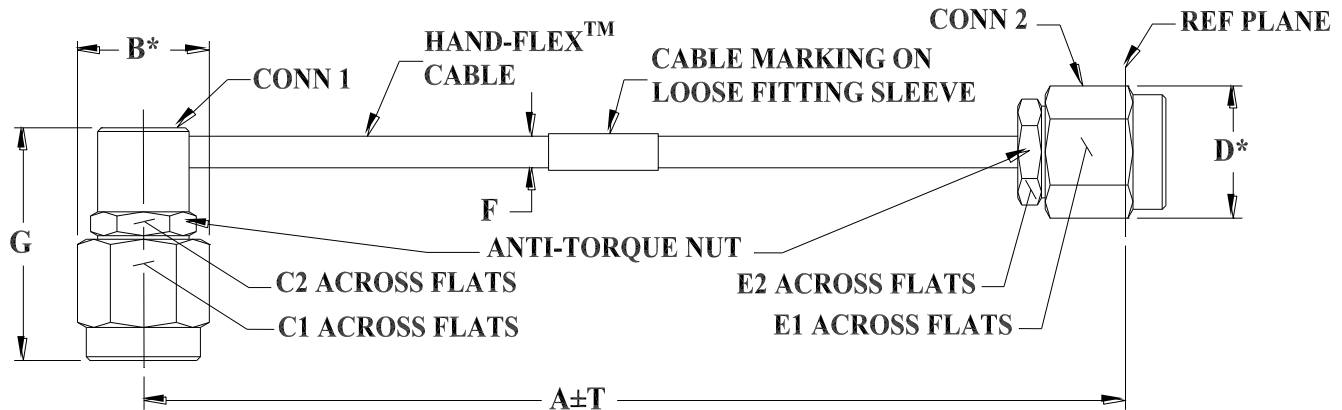

* OVERALL CONNECTOR DIMENSION
(CONNECTOR SHAPE MAY VARY)

KP1573 SERIES
RIGHT ANGLE SMA MALE (CONN-1)
SMA MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		G	H	T		WEIGHT GRAMS	
	INCH	MM							086U-ASMRSM+	086-ASMRSM+			INCH	MM		
KP1573-3	3.00	76.20	.36 (9.14)	.313 (7.95)	.250 (6.35)	.36 (9.14)	.313 (7.95)	.250 (6.35)	.089 ∇ .002 (2.26 ∇ .05)	.108 NOM (2.74 NOM)	.634 (16.10)	--	--	.05	1.27	7.37
KP1573-4	4.00	101.60												.05	1.27	7.83
KP1573-5	5.00	127.00												.05	1.27	8.27
KP1573-6	6.00	152.40												.05	1.27	8.74
KP1573-7	7.00	177.80												.10	2.54	9.20
KP1573-8	8.00	203.20												.10	2.54	9.66
KP1573-9	9.00	228.60												.10	2.54	10.11
KP1573-10	10.00	254.00												.10	2.54	10.57
KP1573-11	11.00	279.40												.10	2.54	11.03
KP1573-12	12.00	304.80												.10	2.54	11.48
KP1573-14	14.00	355.60												.15	3.81	12.40
KP1573-15	15.00	381.00												.15	3.81	12.86
KP1573-16	16.00	406.40												.15	3.81	13.31
KP1573-24	24.00	609.60												.15	3.81	16.97

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. \pm .03; 3Pl. \pm .015

Note:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" represents length of cable.



INTERNET <http://www.minicircuits.com>
 P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661
 Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010
 Mini-Circuits ISO 9001 & ISO 14001 Certified