


Outline Dimensions

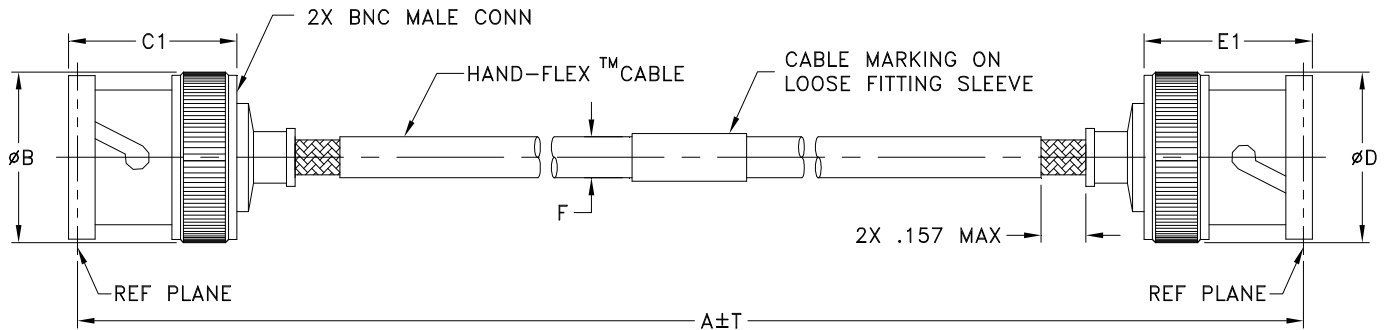

KP2467 SERIES
BNC MALE (CONN-1)
BNC MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		T		WEIGHT GRAMS
	INCH	MM							086U-ABM+	086-ABM+	INCH	MM	
KP2467-6	6.00	152.40	.57 (14.5)	.59 (14.9)	-	.57 (14.5)	.59 (14.9)	-	.089±.002 (2.26±0.05)	.108 NOM (2.72 NOM)	.05	1.27	23.14
KP2467-8	8.00	203.20									.10	2.54	24.06
KP2467-10	10.00	254.00									.10	2.54	24.97
KP2467-12	12.00	304.80									.10	2.54	25.88
KP2467-18	18.00	457.20									.15	3.81	28.63
KP2467-24	24.00	609.60									.15	3.81	31.37

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

1. 141 Hand-Flex™ Coaxial Cable.
2. "A" represents length of cable.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified