


Case Style

KP

Outline Dimensions

KP3379

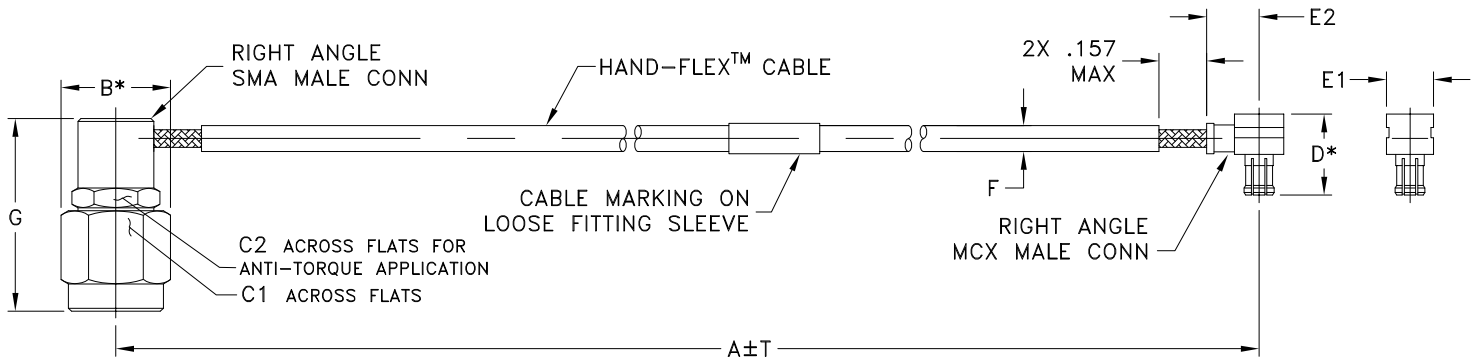

* OVERALL CONNECTOR DIMENSION
[CONNECTOR SHAPE MAY VARY]

Case Style #	A		B	C1	C2	D	E1	E2	F		G	H	T		WT. GRAMS
	INCH	MM							086U-ASMRMCR+	086-ASMRMCR+			INCH	MM	
KP3379-6	6.00	152.40	.36 (9.14)	.315 (8.00)	.250 (6.35)	.335 (8.5)	.197 (5.00)	.22 (5.6)	.089±.002 (2.26±.05)	.108 NOM (2.74 NOM)	.634 (16.10)	-	.05	1.27	7.94
KP3379-7	7.00	177.80											.10	2.54	8.40
KP3379-8	8.00	203.20											.10	2.54	8.86
KP3379-9	9.00	228.60											.10	2.54	9.31
KP3379-10	10.00	254.00											.10	2.54	9.77
KP3379-11	11.00	279.40											.10	2.54	10.23
KP3379-12	12.00	304.80											.10	2.54	10.68
KP3379-18	18.00	457.20											.15	3.81	13.43
KP3379-24	24.00	609.60											.15	3.81	16.17
KP3379-70.9	70.87	1800.00											.40	10.16	37.59
KP3379-118	118.11	3000.00											.79	20.00	59.18

Unless Otherwise Specified dimensions are in inches [mm],
Tolerances: 2 Pl.±0.03; 3 Pl. ±0.015 inches

Notes:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS