


Case Style

KP

Outline Dimensions

KP3498

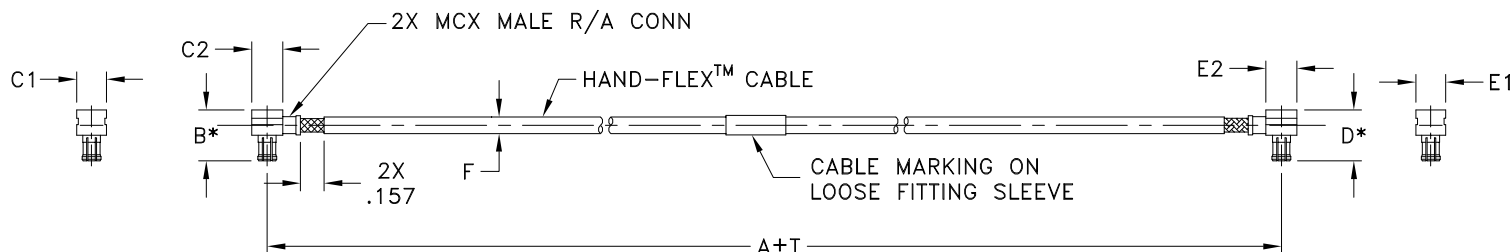

* OVERALL CONNECTOR DIMENSION
[CONNECTOR SHAPE MAY VARY]

Case Style #	A		B	C1	C2	D	E1	E2	F		G	H	T		WT. GRAMS
	INCH	MM							086U-AMCR+	086-AMCR+			INCH	MM	
KP3498-6	6.00	152.40	.335 (8.5)	.197 (5.0)	.22 (5.6)	.335 (8.5)	.197 (5.0)	.22 (5.6)	.089±.002 (2.26±.05)	.108 NOM (2.74 NOM)	-	-	.05	1.27	6.14
KP3498-12	12.00	304.80											.10	2.54	8.89
KP3498-16	16.00	406.40											.15	3.81	10.72
KP3498-18	18.00	457.20											.15	3.81	11.63
KP3498-19	19.00	482.60											.15	3.81	12.09
KP3498-22	22.00	558.80											.15	3.81	13.46
KP3498-24	24.00	609.60											.15	3.81	14.37

Unless Otherwise Specified dimensions are in inches [mm],
Tolerances: 2 Pl.±0.03; 3 Pl. ±0.015 inches

Notes:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS