


# Case Style

# KP

## Outline Dimensions

## KP3827

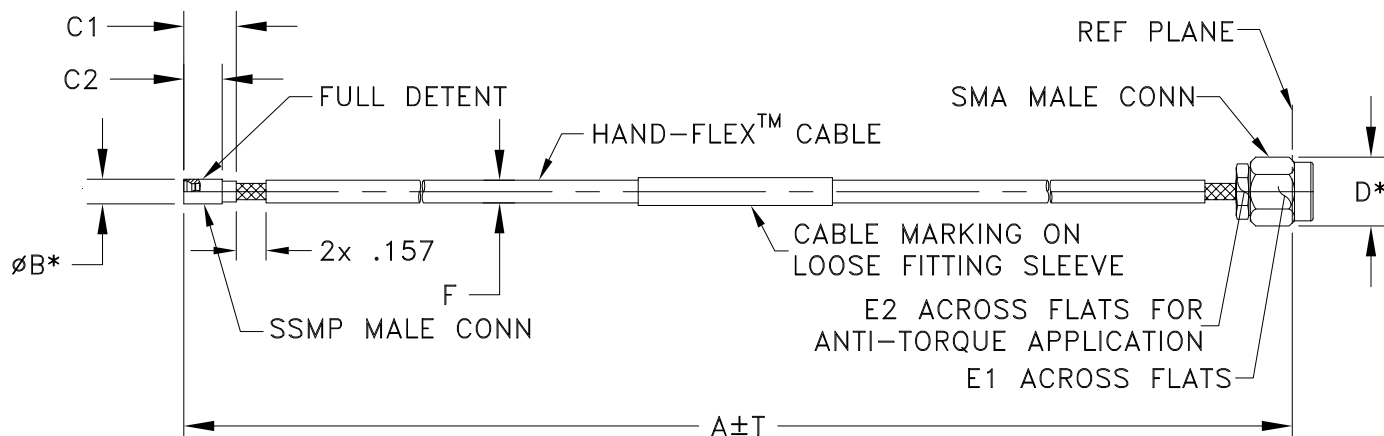

\* OVERALL CONNECTOR DIMENSION  
[CONNECTOR SHAPE MAY VARY]

Case Style #	A		B	C1	C2	D	E1	E2	F		T		WT. (GRAMS)
	INCH	MM							086UC-ASSMPMSM+ 086U-ASSMPMSM+	086C-ASSMPMSM+ 086-ASSMPMSM+	INCH	MM	
KQ3827-3.94	3.94	100.00									.05	1.27	5.40
KQ3827-7.87	7.87	200.00									.10	2.54	6.80
KQ3827-11.8	11.81	300.00									.10	2.54	8.20
KQ3827-19.7	19.69	500.00	.13 [3.28]	.276 [7.00]	.202 [5.12]	.36 [9.14]	.315 [8.00]	.250 [6.35]	.091 MAX [2.31 MAX]	.123 MAX [3.12 MAX]	.15	3.81	11.00

Unless Otherwise Specified dimensions are in inches [mm],

Tolerances: 2 Pl. ±0.03; 3 Pl. ±0.015 inches

Notes:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.

**Mini-Circuits®**  
ISO 9001 ISO 14001 CERTIFIED

ALL NEW  
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS