


Case Style

KP

Outline Dimensions

KP3866

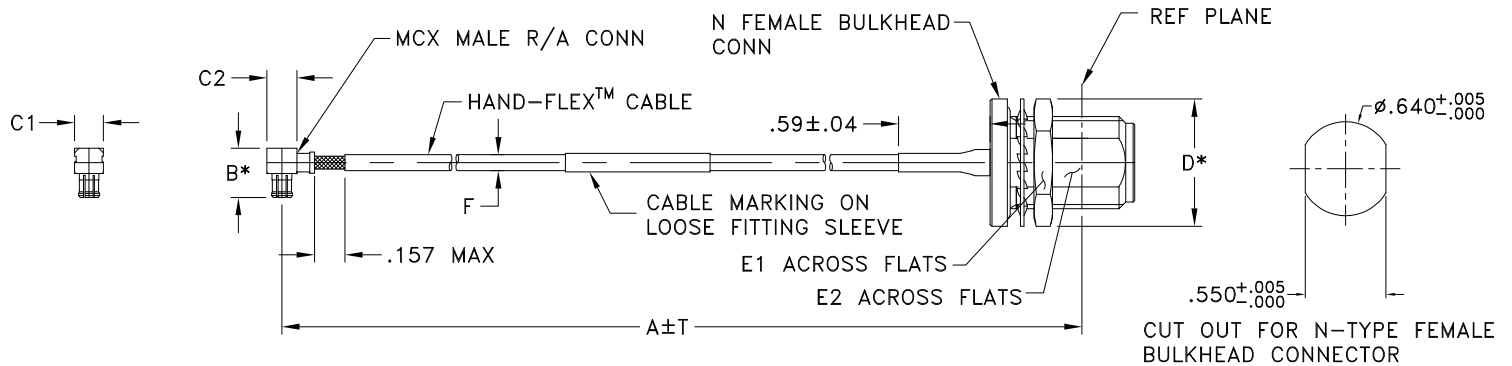

* OVERALL CONNECTOR DIMENSION
[CONNECTOR SHAPE MAY VARY]

Case Style #	A		B	C1	C2	D	E1	E2	F		G	H	T		WT. GRAMS
	INCH	MM							086U-AMCRNB+	086-AMCRNB+			INCH	MM	
KP3866-12	12.00	304.80											.10	2.54	46.58
KP3866-24	24.00	609.60	.335 (8.5)	.197 (5.0)	.22 (5.6)	.87 (22.10)	.750 (19.05)	.531 (13.49)	.089±.002 (2.26±.05)	.108 NOM (2.74 NOM)	—	—	.15	3.81	52.07
KP3866-36	36.00	914.00											.20	5.08	57.55
KP3866-48	48.00	1219.20											.30	7.62	63.04
KP3866-60	60.00	1524.00											.40	10.16	68.52

Unless Otherwise Specified dimensions are in inches [mm],
Tolerances: 2 Pl. ±0.03; 3 Pl. ±0.015 inches

Notes:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS