


Outline Dimensions

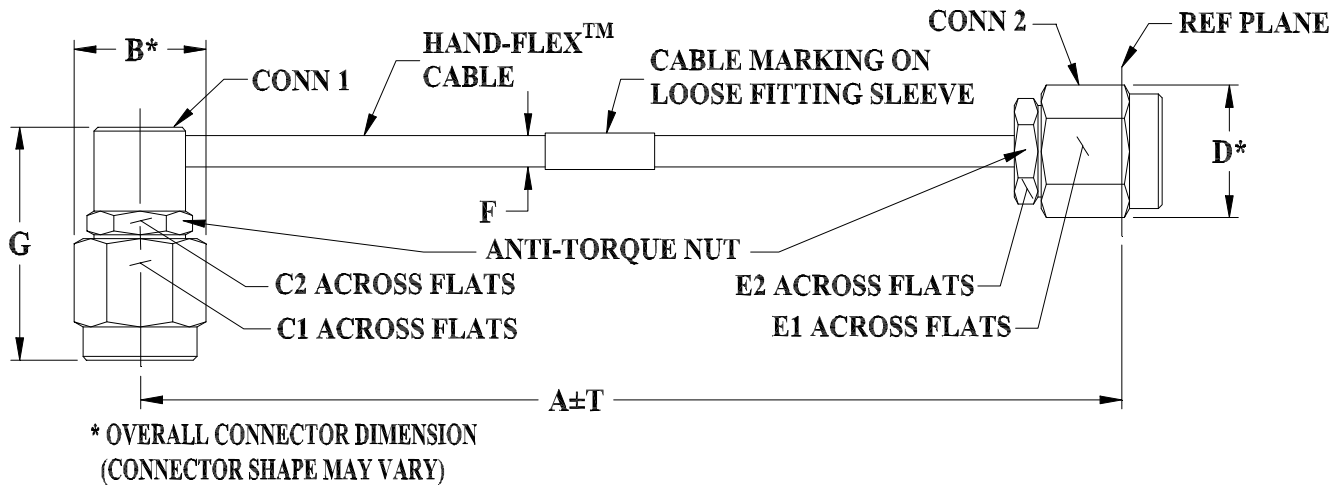

KQ1612 SERIES
 RIGHT ANGLE SMA MALE (CONN-1)
 SMA MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		G	H	T		WEIGHT GRAMS	
	INCH	MM							141U- ASMRSM+	141- ASMRSM+			INCH	MM		
KQ1612-3	3.00	76.20	.36 (9.14)	.313 (7.95)	.250 (6.35)	.36 (9.14)	.313 (7.95)	.250 (6.35)	.141±.003 (3.58±0.07)	.163±.004 (4.14±0.10)	.728±.020 (18.50±0.50)	--	--	.05	1.27	8.83
KQ1612-4	4.00	101.60												.05	1.27	9.77
KQ1612-5	5.00	127.00												.05	1.27	10.92
KQ1612-.5.5	5.50	139.70												.05	1.27	11.49
KQ1612-6	6.00	152.40												.05	1.27	12.26
KQ1612-7	7.00	177.80												.10	2.54	13.20
KQ1612-8	8.00	203.20												.10	2.54	14.34
KQ1612-9	9.00	228.60												.10	2.54	15.49
KQ1612-10	10.00	254.00												.10	2.54	16.63
KQ1612-11	11.00	279.40												.10	2.54	17.77
KQ1612-12	12.00	304.80												.10	2.54	19.12
KQ1612-13	13.00	330.20												.15	3.81	20.06
KQ1612-14	14.00	355.60												.15	3.81	21.20

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

1. 141 Hand-Flex™ Coaxial Cable.
2. "A" represents length of cable.

Mini-Circuits®

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Outline Dimensions

KQ1612 SERIES
 RIGHT ANGLE SMA MALE (CONN-1)
 SMA MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		G	H	T		WEIGHT GRAMS
	INCH	MM							141U-ASMRSM+	141-ASMRSM+			INCH	MM	
KQ1612-15	15.00	381.00	.36 (9.14)	.313 (7.95)	.250 (6.35)	.36 (9.14)	.313 (7.95)	.250 (6.35)	.141±.003 (3.58±0.07)	.163±.004 (4.14±0.10)	.728±.020 (18.50±0.50)	-- --	.15	3.81	22.35
KQ1612-16	16.00	406.40											.15	3.81	23.49
KQ1612-17	17.00	431.80											.15	3.81	24.63
KQ1612-18	18.00	457.20											.15	3.81	25.77
KQ1612-20	20.00	508.00											.15	3.81	28.06
KQ1612-24	24.00	609.60											.15	3.81	32.63
KQ1612-32	32.00	812.80											.20	5.08	41.78
KQ1612-36	36.00	914.40											.20	5.08	46.35

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified