


## Outline Dimensions

## KQ3755

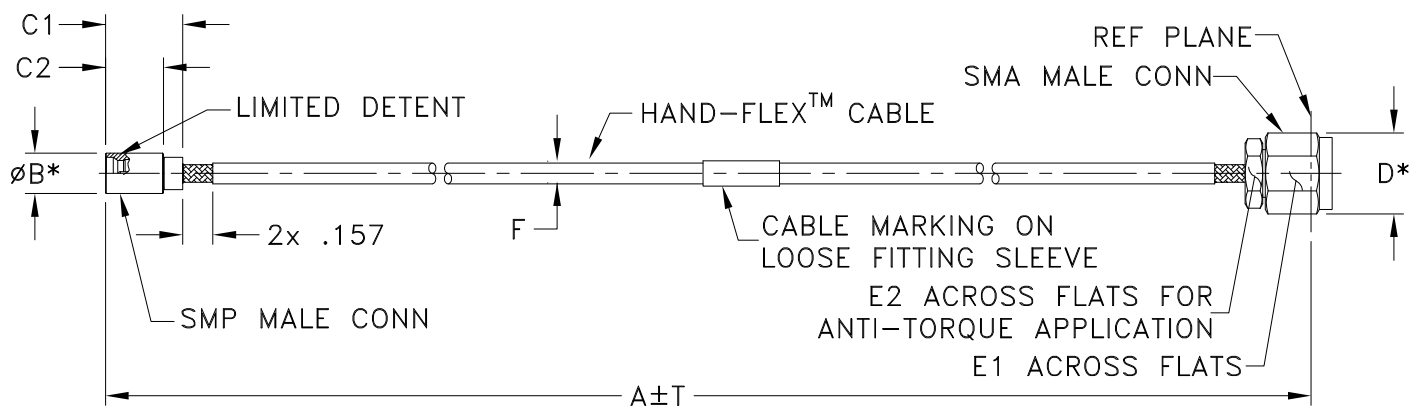

\* OVERALL CONNECTOR DIMENSION  
[CONNECTOR SHAPE MAY VARY]

CASE STYLE #	A		B	C1	C2	D	E1	E2	F		T		WT. (GRAMS)
	INCH	MM							141UC-ASMPMSM+ 141U-ASMPMSM+	141C-ASMPMSM+ 141-ASMPMSM+	INCH	MM	
KQ3755-3.94	3.94	100.00									.05	1.27	7.80
KQ3755-7.87	7.87	200.00									.10	2.54	12.30
KQ3755-11.8	11.81	300.00	.18	.346	.260	.36	.315	.250	.141±.003	.163±.004	.10	2.54	16.79
KQ3755-19.7	19.69	500.00	[4.60]	[8.80]	[6.60]	[9.14]	[8.00]	[6.35]	[3.58±0.07]	[4.14±0.10]	.15	3.81	25.82

Unless Otherwise Specified dimensions are in inches [mm],  
Tolerances: 2 Pl.±0.03; 3 Pl. ±0.015 inches

### Notes:

- 141 Hand-Flex™ Coaxial Cable.
- "A" Represents Length of Cable.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS