


Case Style

LM


Outline Dimensions

LM2795


TOP VIEW

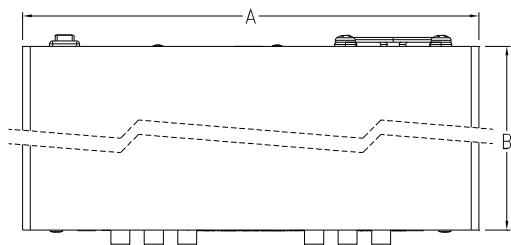

FRONT VIEW

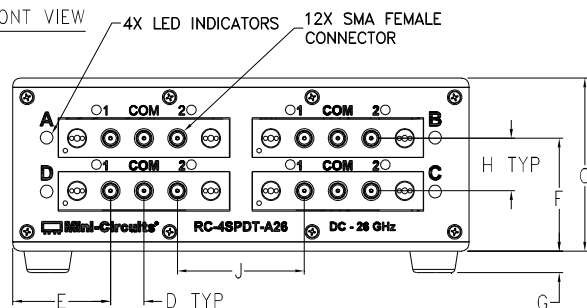


REAR VIEW

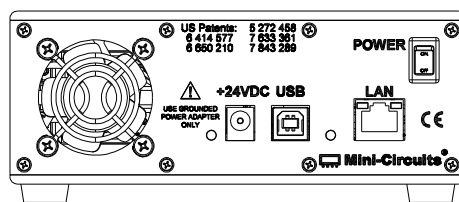


BOTTOM VIEW

SHOW WITH RUBBER FEET REMOVED
AND BRACKETS INSTALLED

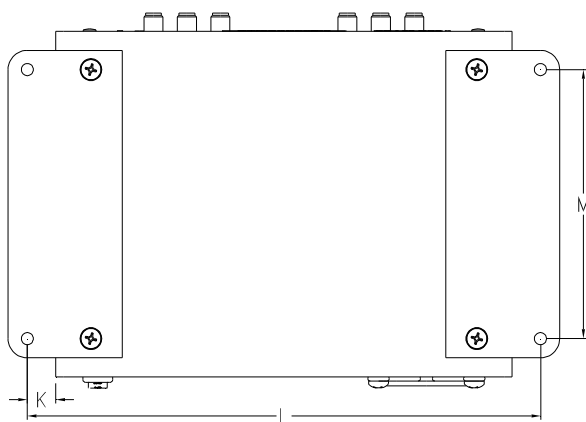

BRACKET OPTION
ONE SET OF 2 EACH

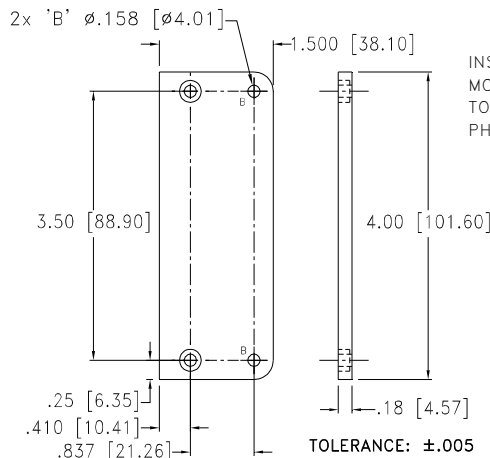

INSTRUCTION FOR
MOUNTING BRACKETS:
TOOL REQUIRED:
PHILLIPS HEAD SCREW DRIVER
STEP 1: REMOVE RUBBER FEET
FROM THE BOTTOM
OF THE UNIT,
DO NOT DISCARD
THE FASTENERS.
STEP 2: MOUNT THE BRACKETS
WITH THE FASTENERS
REMOVED IN STEP 1,
USING THE COUNTER
BORE HOLES IN THE
BRACKET.

CASE#	A	B	C	D	E	F	G	H	J	K	L	M	WT. GRAMS
LM2795	6.00 (152.4)	4.50 (114.3)	2.25 (57.2)	.440 (11.18)	1.28 (32.5)	1.47 (37.3)	.28 (7.11)	.688 (17.5)	1.670 (42.4)	.375 (9.52)	6.75 (171.4)	3.500 (88.9)	1184

Dimensions are in inches (mm). Tolerances: 2PL. +/- .03; 3PL. +/- .015

Notes:

1. Case and Bracket material: Aluminum Alloy.
2. Finish: For Case- Powder coating. Color: Blue, For Bracket- Clear Chemical conversion coating.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS