


## Outline Dimensions

NS1992

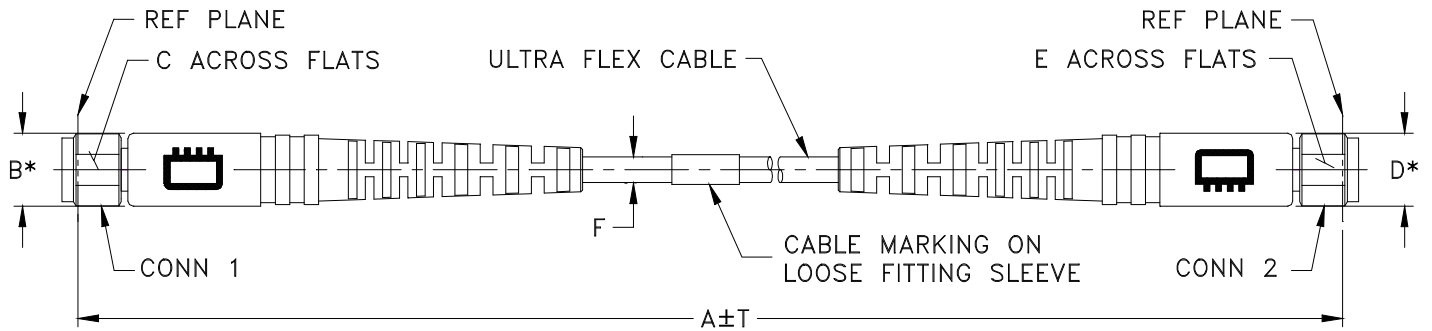

\* OVERALL CONNECTOR/BOOT DIMENSION  
[CONNECTOR/BOOT SHAPE MAY VARY]

NS1992 SERIES  
SMA MALE (CONN-1)  
SMA MALE (CONN-2)

CASE STYLE #	A		B	C	D	E	F	T		WEIGHT GRAMS
	FEET	METERS						FEET	METERS	
NS1992-1	1.00	0.30	.426 [10.82]	.313 [7.95]	.426 [10.82]	.313 [7.95]	.150±.004 [3.81±0.10]	.06	0.02	34
NS1992-1.5	1.50	0.46						.06	0.02	39
NS1992-2	2.00	0.61						.06	0.02	44
NS1992-3	3.00	0.91						.09	0.03	53
NS1992-3.28	3.28	1.00						.10	0.03	56
NS1992-4	4.00	1.22						.12	0.04	63
NS1992-6	6.00	1.83						.18	0.05	82
NS1992-6.56	6.56	2.00						.20	0.06	87
NS1992-8	8.00	2.44						.24	0.07	101
NS1992-10	10.00	3.05						.30	0.09	120

Tolerances: 2Pl. ± .03; 3Pl. ± .015

### Note:

1. Flexible Coaxial Cable.

**Mini-Circuits®**

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified