


## Outline Dimensions

NS1993

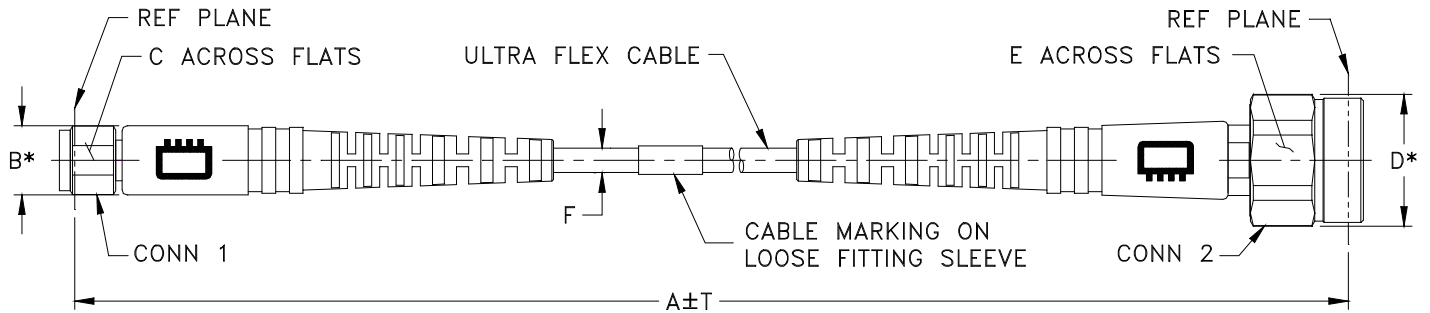

\* OVERALL CONNECTOR/BOOT DIMENSION  
[CONNECTOR/BOOT SHAPE MAY VARY]

NS1993 SERIES  
SMA MALE (CONN-1)  
N-Type MALE (CONN-2)

CASE STYLE #	A		B	C	D	E	F	T		WEIGHT GRAMS
	FEET	METERS						FEET	METERS	
NS1993-1	1.00	0.30	.426 [10.82]	.313 [7.98]	.812 [20.62]	.750 [19.05]	.150±.004 [3.81±0.10]	.06	0.02	56
NS1993-2	2.00	0.61						.06	0.02	65
NS1993-3	3.00	0.91						.09	0.03	75
NS1993-3.28	3.28	1.00						.10	0.03	77
NS1993-4	4.00	1.22						.12	0.04	84
NS1993-6	6.00	1.83						.18	0.05	103

Tolerances: 2Pl. ± .03; 3Pl. ± .015

### Note:

1. Ultra Flex Coaxial Cable.
2. "A" Represents Length of Cable.

**Mini-Circuits®**

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified