



Outline Dimensions

PQ2481



TOP SIDE

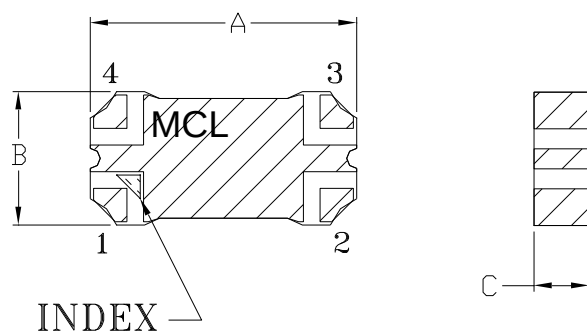


PCB LAND PATTERN

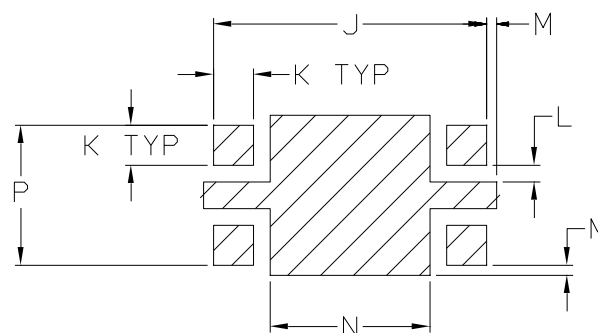

BOTTOM SIDE

 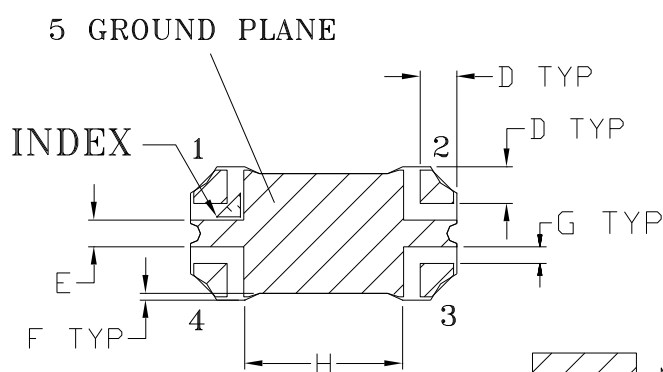

METALLIZATION

 

SOLDER RESIST

CASE#	A	B	C	D	E	F	G	H	J	K	L	M	N	P	WT. GRAMS
PQ2481	.400 (10.16)	.200 (5.08)	.083 (2.11)	.055 (1.40)	.030 (0.76)	.010 (0.25)	.025 (0.63)	.237 (6.02)	.410 (10.41)	.060 (1.52)	.025 (0.63)	.015 (0.38)	.240 (6.10)	.210 (5.33)	1.0

Dimensions are in inches (mm). Tolerances: 2PL. +/- .03; 3PL. +/- .010

Notes:

1. Base material: Printed wiring laminate.
2. Termination finish:
For RoHS Cases, all models (+) suffix: 2-5 μ inch (.05-.13 microns) Immersion Gold.
For RoHS-5 Cases, all models no (+) suffix: Tin-Lead plate.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661
Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010
Mini-Circuits ISO 9001 & ISO 14001 Certified