


# Case Style

# RB

## Outline Dimensions

## RB2574

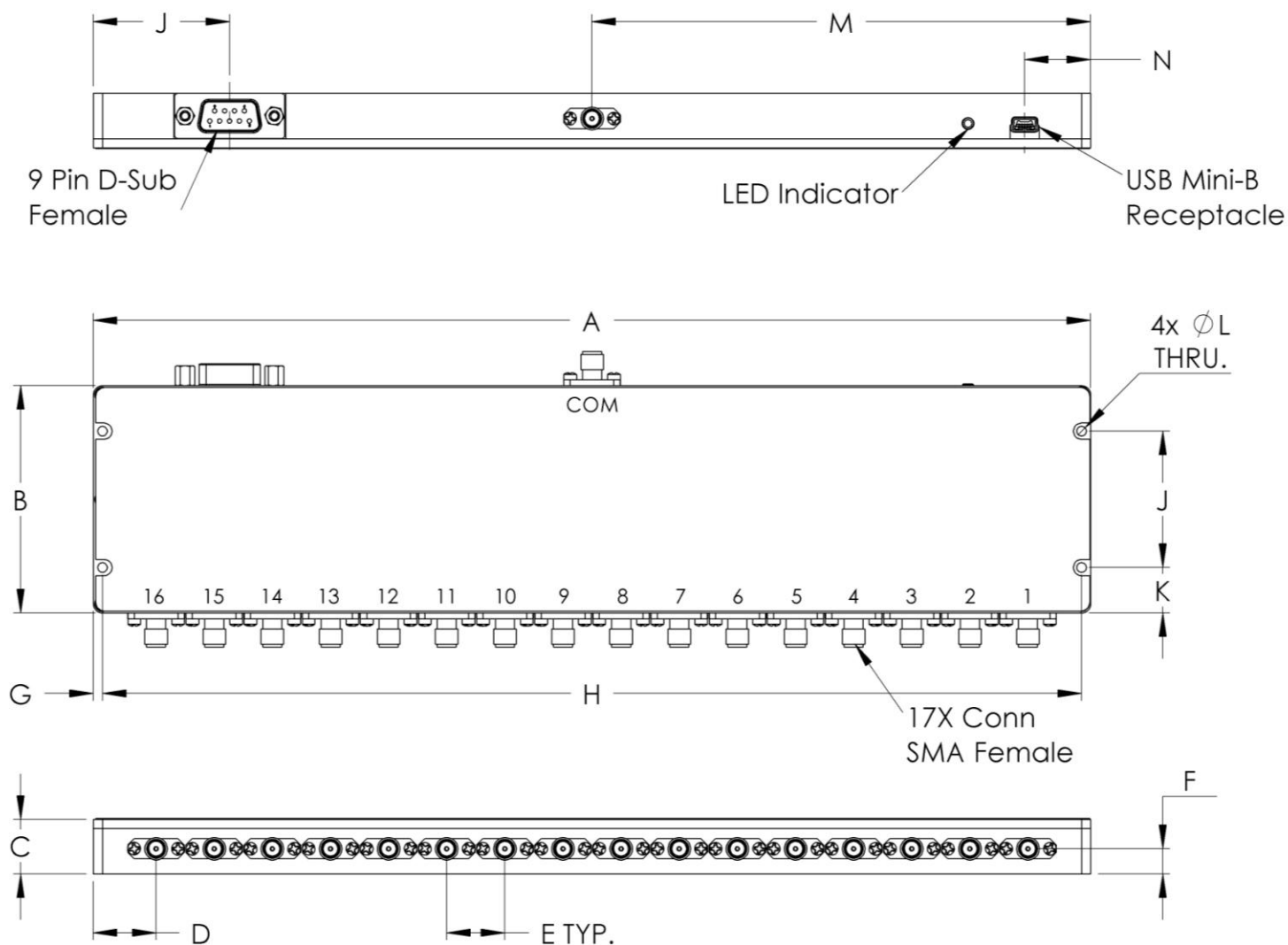

| CASE#  | A                | B              | C              | D              | E               | F              | G             | H                  | J                | K             | L              | M                | N             | WT.<br>GRAMS |
|--------|------------------|----------------|----------------|----------------|-----------------|----------------|---------------|--------------------|------------------|---------------|----------------|------------------|---------------|--------------|
| RB2574 | 10.98<br>(278.9) | 2.50<br>(63.5) | .60<br>(15.24) | .69<br>(17.53) | .640<br>(16.26) | .278<br>(7.06) | .10<br>(2.54) | 10.780<br>(273.81) | 1.500<br>(38.10) | .50<br>(12.7) | .106<br>(2.69) | 5.49<br>(139.45) | .73<br>(18.5) | 650          |

Dimensions are in inches (mm). Tolerances: 2PL. +/- .03; 3PL. +/- .015

### Notes:

1. Case material: Aluminum alloy.
2. Case finish for RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified