


Case Style

RJ

RJ2516

Outline Dimensions

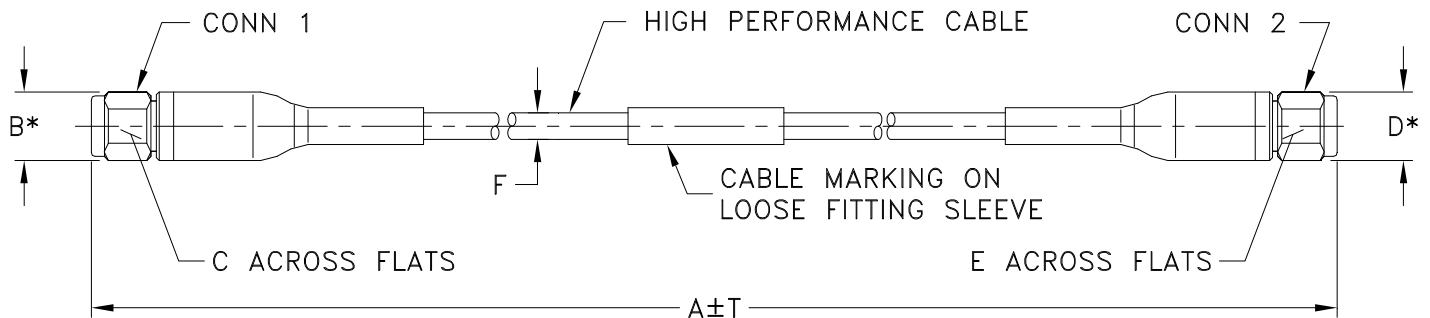

* OVERALL CONNECTOR OR CABLE & BOOT DIM
[CONNECTOR SHAPE MAY VARY]

RJ2516 SERIES
2.92mm MALE (CONN-1)
2.92mm MALE (CONN-2)

CASE STYLE #	A		B	C	D	E	F	T		WEIGHT GRAMS
	FEET	METERS						INCH	MM	
RJ2516-3	3.00	.91	.42 (10.70)	.312 (7.93)	.42 (10.70)	.312 (7.93)	.142 (3.60)	+.08/-0	+2.0/-0	59
RJ2516-3.28	3.28	1.00						+.39/-0	+10.0/-0	61
RJ2516-6	6.00	1.83						+.72/-0	+18.3/-0	89

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

1. High Performance Cable.

Mini-Circuits®

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified