



Outline Dimensions

RS1539

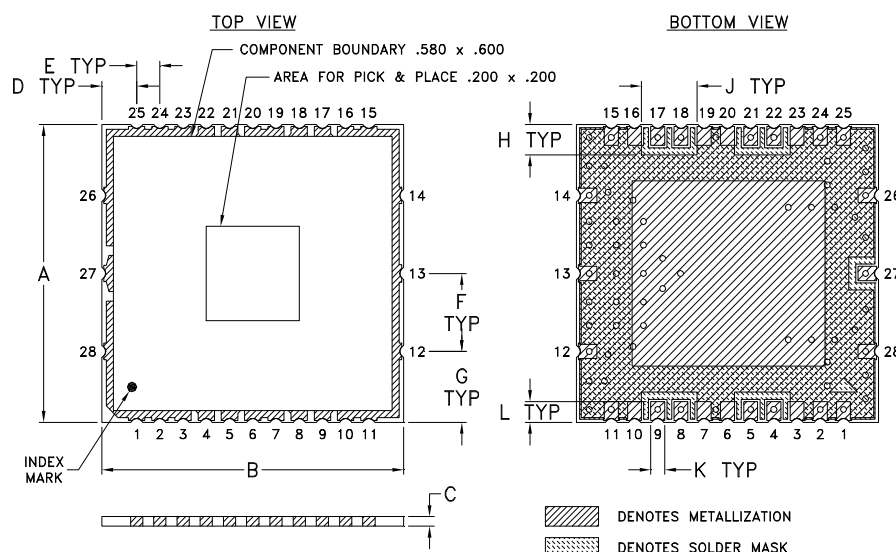

PCB Land Pattern

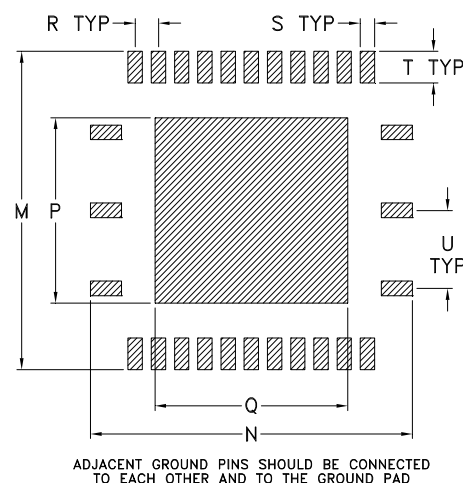

Suggested Layout,
Tolerance to be within $\pm .002$

CASE#	A	B	C	D	E	F	G	H	J	K	L
RS1539	.630 (16.00)	.650 (16.51)	.020 (0.51)	.075 (1.91)	.050 (1.27)	.165 (4.19)	.150 (3.81)	.064 (1.63)	.120 (3.05)	.030 (0.76)	.044 (1.12)

CASE#	M	N	P	Q	R	S	T	U	V	WT.GRAMS
RS1539	.673 (17.09)	.693 (17.60)	.392 (9.96)	.415 (10.54)	.050 (1.27)	.031 (0.79)	.067 (1.70)	.165 (4.19)	--	.35

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .05$; 3 Pl. $\pm .015$

Notes:

- Base material: Printed wiring laminate.
- Termination finish:
 - For RoHS Case Styles: 3-5 μ inch (.08-.13 microns) Gold over 120-240 μ inch (3.05-6.10 microns) Nickel plate. All models, (+) suffix.
 - For RoHS-5 Case Styles: Tin-Lead plate. All models, no (+) suffix.

Mini-Circuits®

INTERNET <http://www.minicircuits.com>
 P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661
 Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010
 Mini-Circuits ISO 9001 & ISO 14001 Certified