


## Outline Dimensions

SE2929

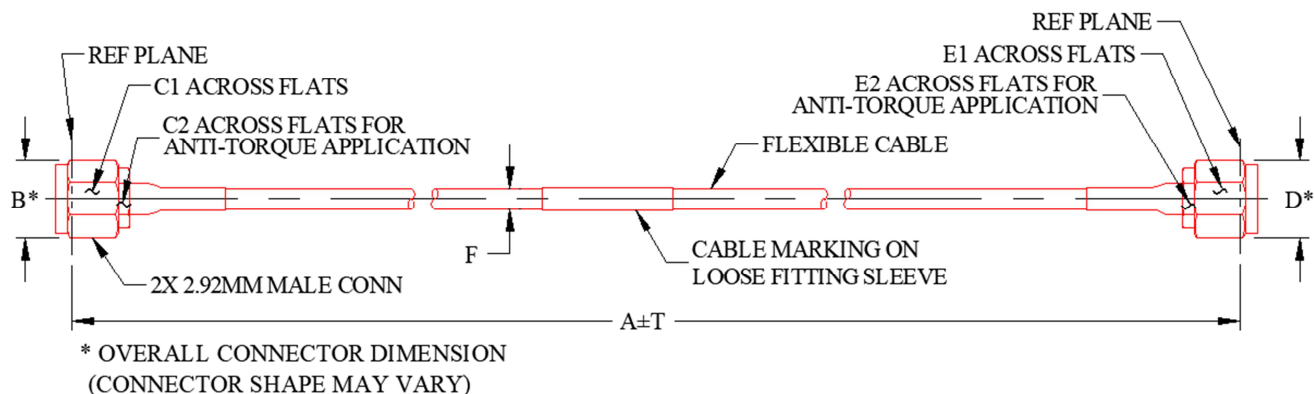

SE2929 SERIES  
2.92MM MALE (CONN)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F FL086-AKM+	T		WEIGHT GRAMS
	INCH	MM								INCH	MM	
SE2929-3	3.00	76.20	.36 (9.14)	.315 (8.00)	.250 (6.35)	.36 (9.14)	.315 (8.00)	.250 (6.35)	.106±.004 (2.64±0.1)	.05	1.27	8.95
SE2929-4	4.00	101.60								.05	1.27	9.40
SE2929-6	6.00	152.40								.05	1.27	10.30
SE2929-12	12.00	304.80								.10	2.54	11.20
SE2929-18	18.00	457.20								.15	3.81	15.70
SE2929-24	24.00	609.60								.15	3.81	18.40
SE2929-60	60.00	1524.00								.40	10.16	34.60

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl.±.03; 3Pl. ± .015

Note:

1. 086 Flexible Coaxial Cable.
2. "A" Represents Length of Cable.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS