


Outline Dimensions

UU1332-1

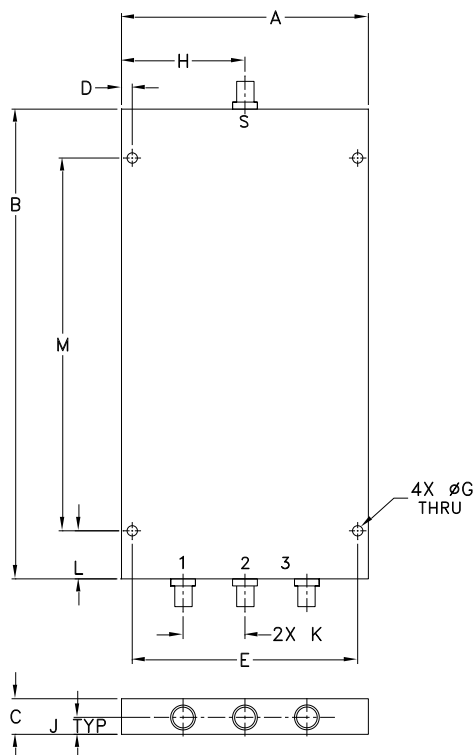

CASE#	A	B	C	D	E	F	G	H	J	K	L	M	WT. GRAMS
UU1332-1	2.99 (75.95)	5.67 (144.02)	.43 (10.92)	.13 (3.30)	2.73 (69.34)	--	.125 (3.18)	1.495 (37.97)	.205 (5.21)	.75 (19.05)	.58 (14.73)	4.500 (114.30)	260

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

- Case material: Aluminum alloy.
- Case finish:
For RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based.
- Refer to the individual model data sheet for the type of connectors available.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS