


Outline Dimensions

UU2046

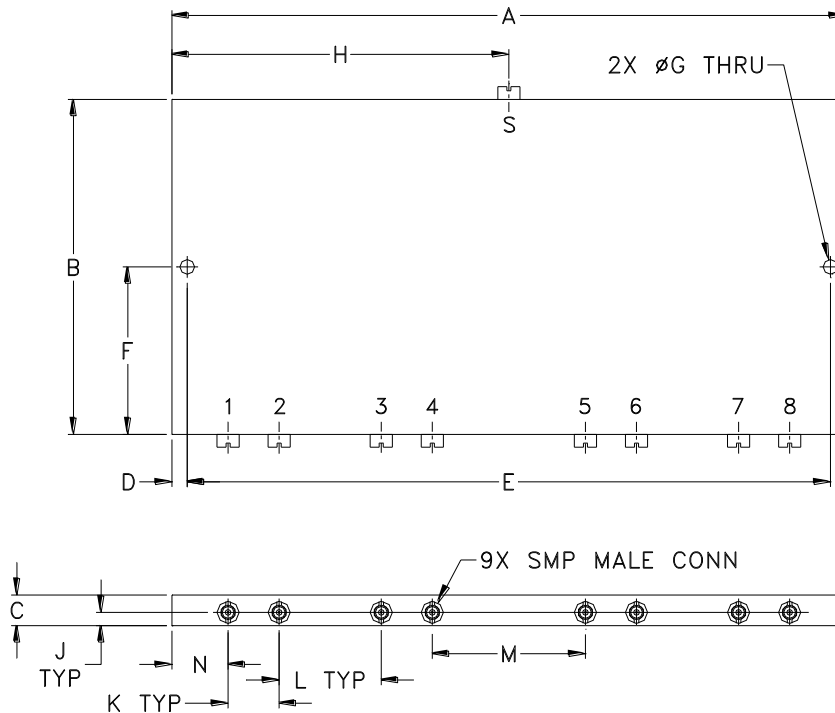

CASE#	A	B	C	D	E	F	G	H	J	K	L
UU2046	6.60 (167.64)	3.28 (83.31)	.30 (7.62)	.150 (3.81)	6.300 (160.02)	1.64 (41.66)	.144 (3.66)	3.30 (83.82)	.13 (3.30)	.500 (12.70)	1.000 (25.40)

CASE#	M	N	P	WT, GRAMS
UU2046	1.500 (38.10)	.550 (13.97)	-- --	190

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

- Case material: Aluminum alloy.
- Case finish:
For RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based.
- Refer to the individual model data sheet for the type of connectors available.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS