


Case Style

UU

Outline Dimensions

UU2358-1

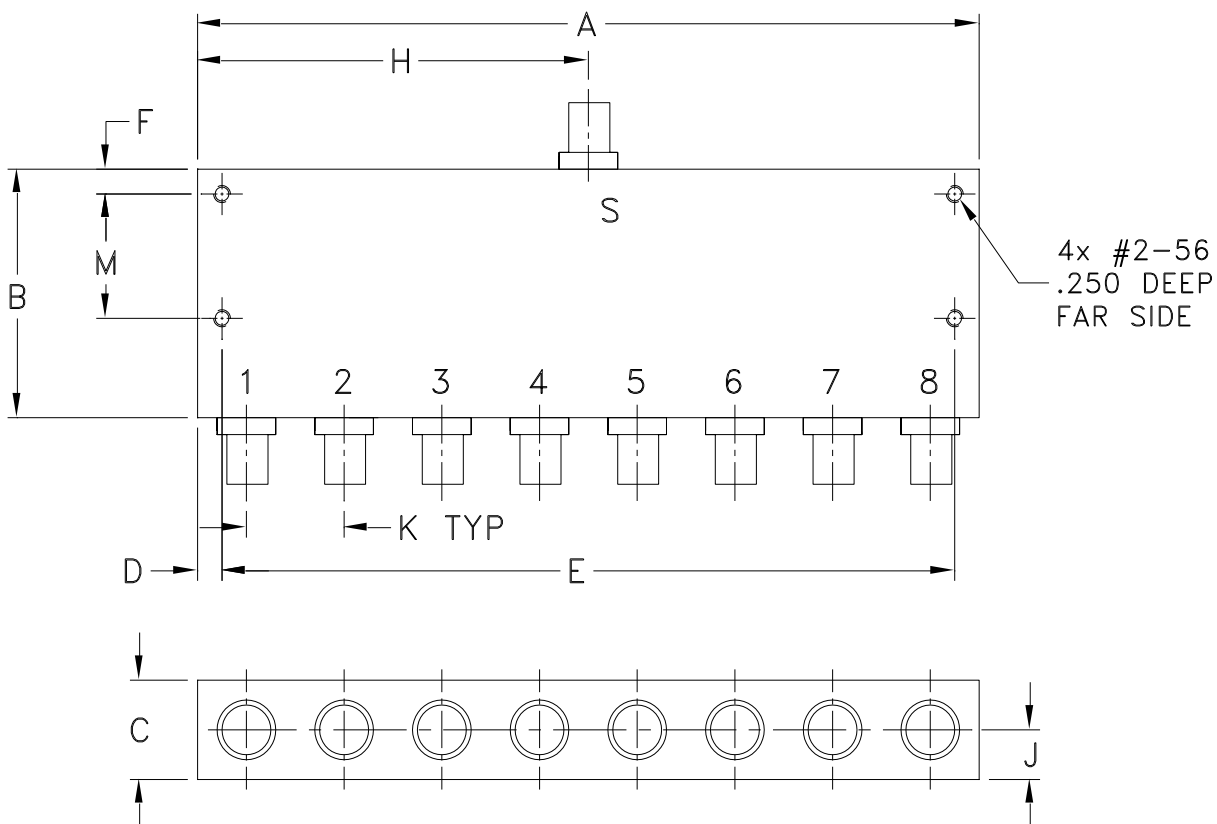

CASE#	A	B	C	D	E	F	G	H	J	K	L	M	WT. GRAMS
UU2358-1	4.00 (101.60)	1.25 (31.75)	.50 (12.70)	.125 (3.18)	3.750 (95.25)	.125 (3.18)	-- --	2.00 (50.80)	.25 (6.35)	.500 (12.70)	-- --	.625 (15.87)	85

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

1. Case material: Aluminum alloy.
2. Case finish:
For RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based.
3. Refer to the individual model data sheet for the type of connectors available.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS