


Case Style

UU

Outline Dimensions

UU2412

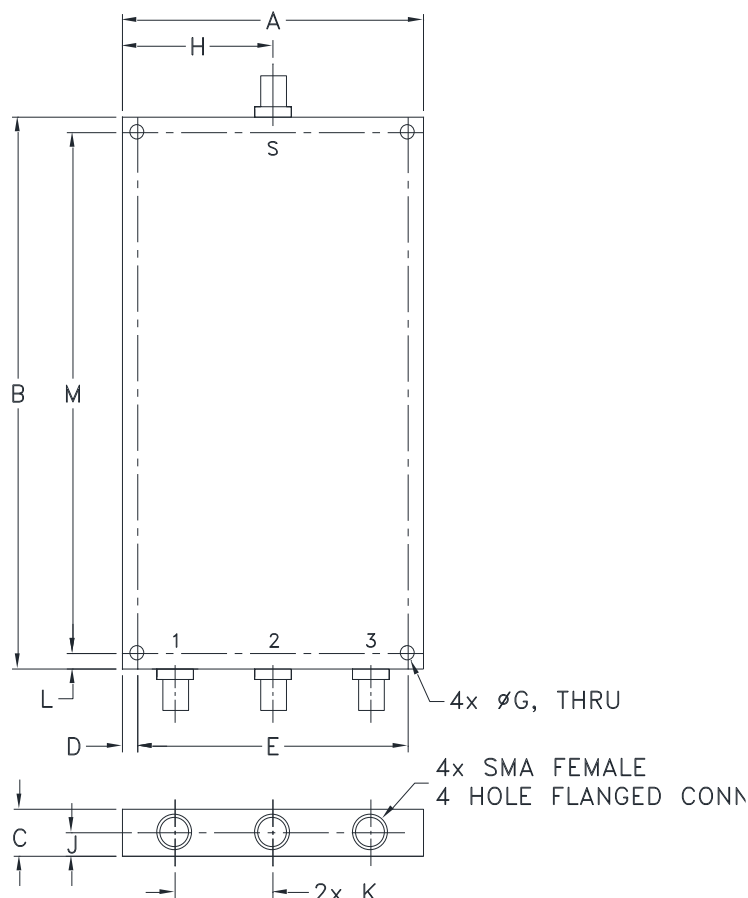

CASE#	A	B	C	D	E	F	G	H	J	K	L	M
UU2412	2.46 (62.48)	4.46 (113.28)	.38 (9.65)	.13 (3.18)	2.210 (56.13)	-- --	.129 (3.28)	1.23 (31.24)	.19 (4.83)	.800 (20.32)	.13 (3.18)	4.210 (106.93)

CASE#	N	WT. GRAMS
UU2412	-- --	340

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

- Case material: Aluminum alloy.
- Case finish:
For RoHS Case Styles: Blue Painting Pantone 286.
- Refer to the individual model data sheet for the type of connectors available.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS