


Outline Dimensions

UU2413-6

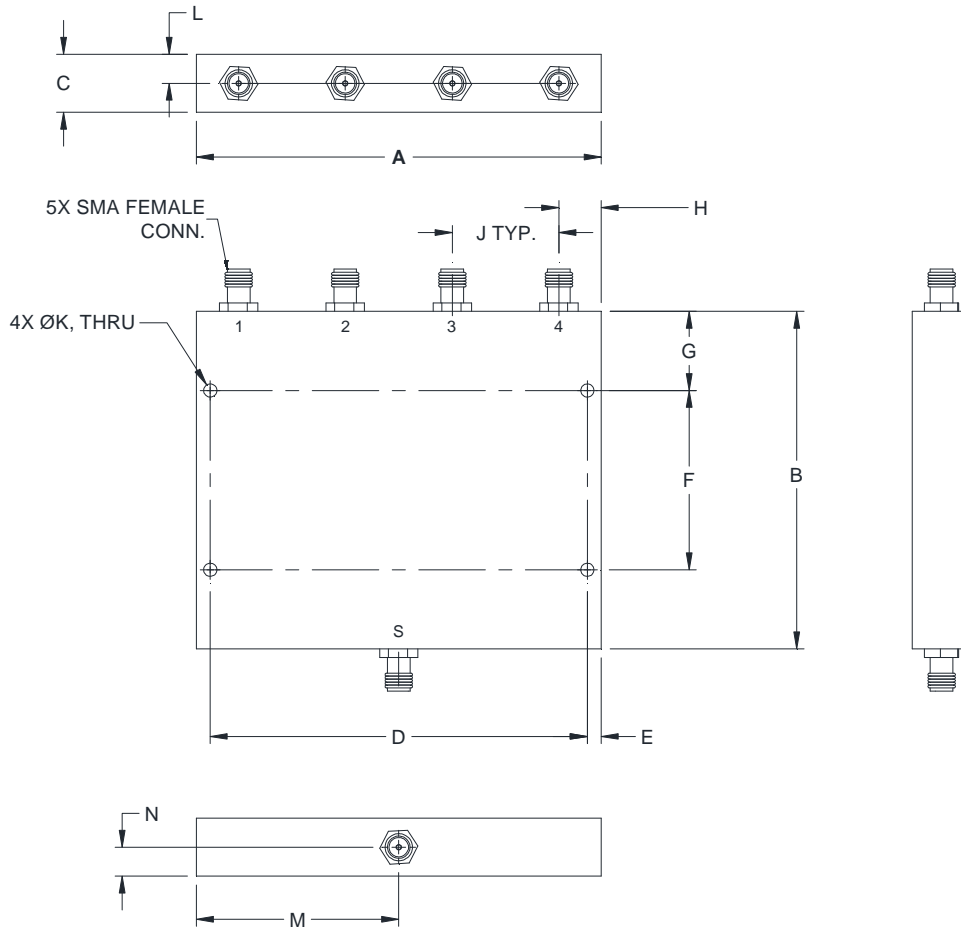

CASE#	A	B	C	D	E	F	G	H	J	K	L
UU2413-6	3.80 (96.5)	3.20 (81.3)	.55 (14.0)	3.540 (89.92)	.130 (3.30)	1.700 (43.18)	.750 (19.05)	.40 (10.1)	1.00 (25.4)	.125 (3.18)	.28 (7.0)

CASE#	M	N	WT, GRAM
UU2413-6	1.90 (48.26)	.28 (7.0)	85

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

1. Case material: Aluminum Alloy 5052-H32 or 6061-T6 or equivalent
2. Case finish:
For RoHS Case Styles: Clear Chemical Conversion Coating.