


Case Style

UU

Outline Dimensions

UU2624-3

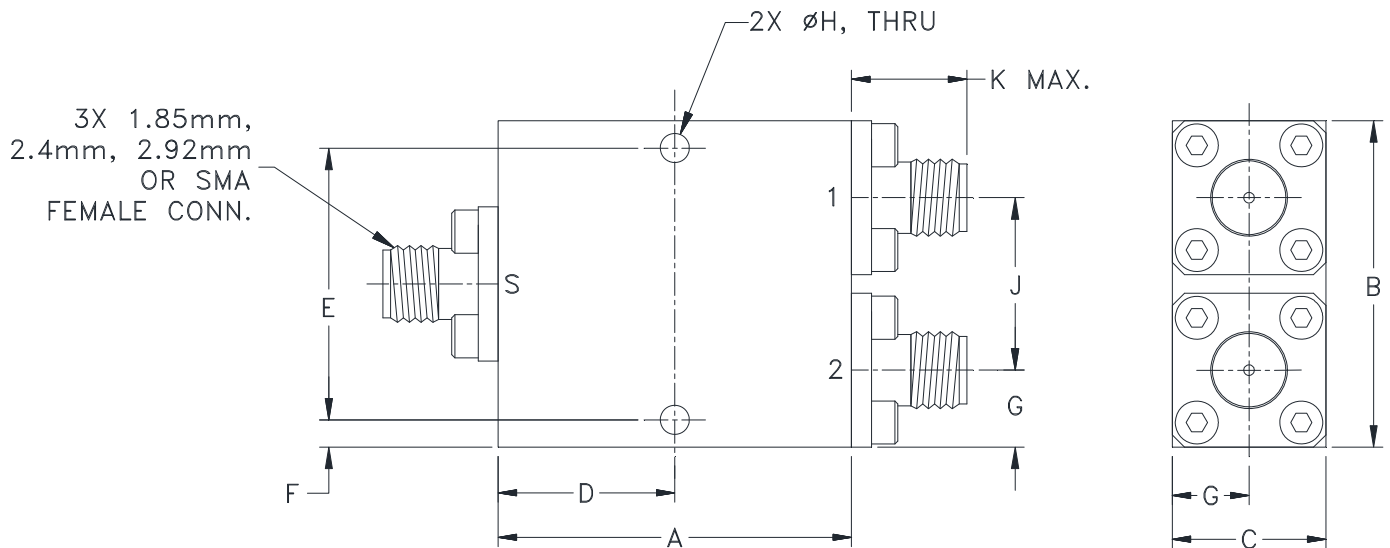

| CASE # | A | B | C | D | E | F | G | H | J | K |
|----------|-----------------|-----------------|----------------|-----------------|-----------------|----------------|---------------|----------------|----------------|---------------|
| UU2624-3 | 1.15 (29.21) | 1.06 (26.92) | .50 (12.70) | .575 (14.60) | .883 (22.42) | .089 (2.25) | .25 (6.35) | .094 (2.40) | .56 (14.22) | .43 (11.0) |

| CASE # | WT. GRAM |
|----------|----------|
| UU2624-3 | 50 |

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

1. Case material: Aluminum alloy.
2. Case finish: Painting Color: Blue.
3. Refer to the individual model data sheet for the type of connectors available.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/MICROWAVE COMPONENTS