


Case Style

UU

Outline Dimensions

UU2625

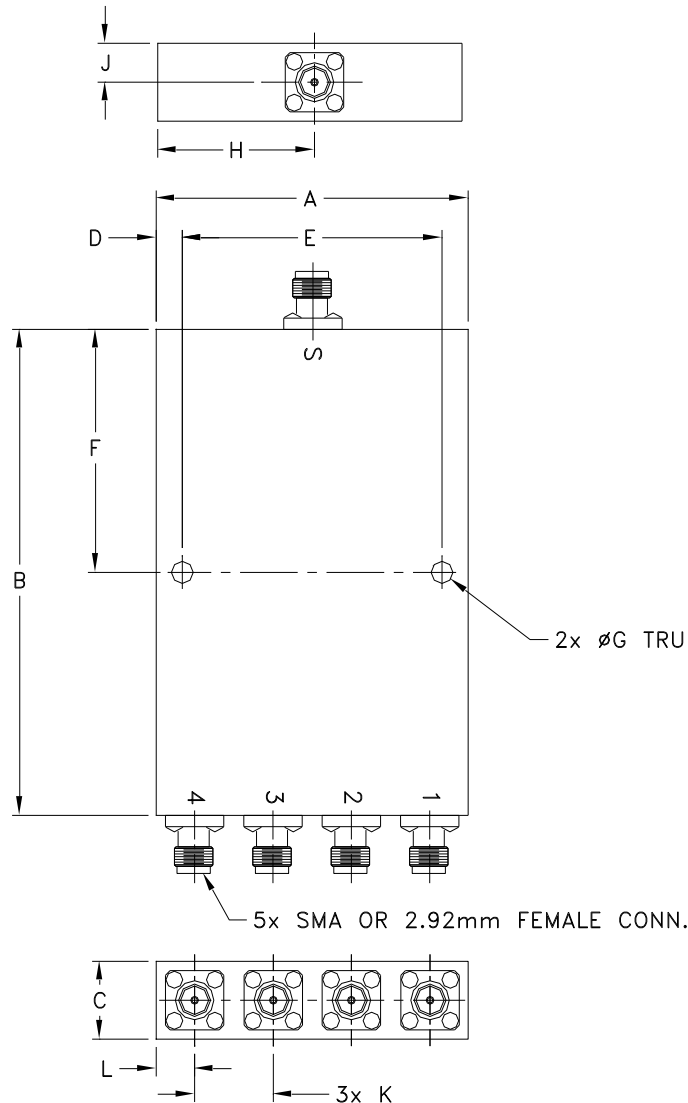

CASE#	A	B	C	D	E	F	G	H	J	K	L	WT. GRAMS
UU2625	2.03 (51.56)	3.12 (79.25)	.50 (12.70)	.17 (4.32)	1.690 (42.93)	1.56 (39.62)	.142 (3.60)	1.02 (25.91)	.25 (6.40)	.512 (13.00)	.25 (6.40)	160

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

1. Case material: Aluminum alloy.
2. Case finish: Painting Color: Blue.
3. Refer to the individual model data sheet for the type of connectors available.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS