


Outline Dimensions

UU640

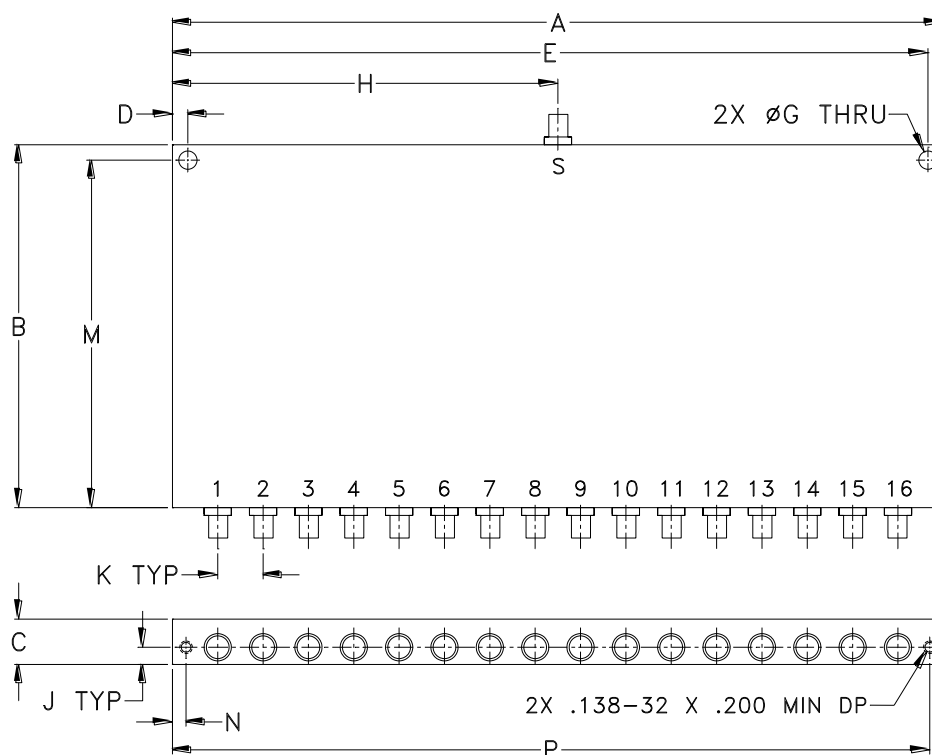

CASE#	A	B	C	D	E	F	G	H	J	K	L	M
UU640	8.50 (215.90)	4.00 (101.60)	.50 (12.70)	.170 (4.32)	8.330 (211.58)	--	.201 (5.11)	4.25 (107.95)	.19 (4.83)	.500 (12.70)	--	3.830 (97.28)

CASE#	N	P	WT. GRAMS
UU640	.150 (3.81)	8.350 (212.09)	450

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

- Case material: Aluminum alloy.
- Case finish:
For RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based.
- Refer to the individual model data sheet for the type of connectors available.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS