


Customer	General		
Model	ZT-184		

**Description:**

Dimensions	19" (W), 3U (H)
	10 ZN4PD1-63HP-S+ mounted on front panel showing all 5 connectors

**Product Photo**

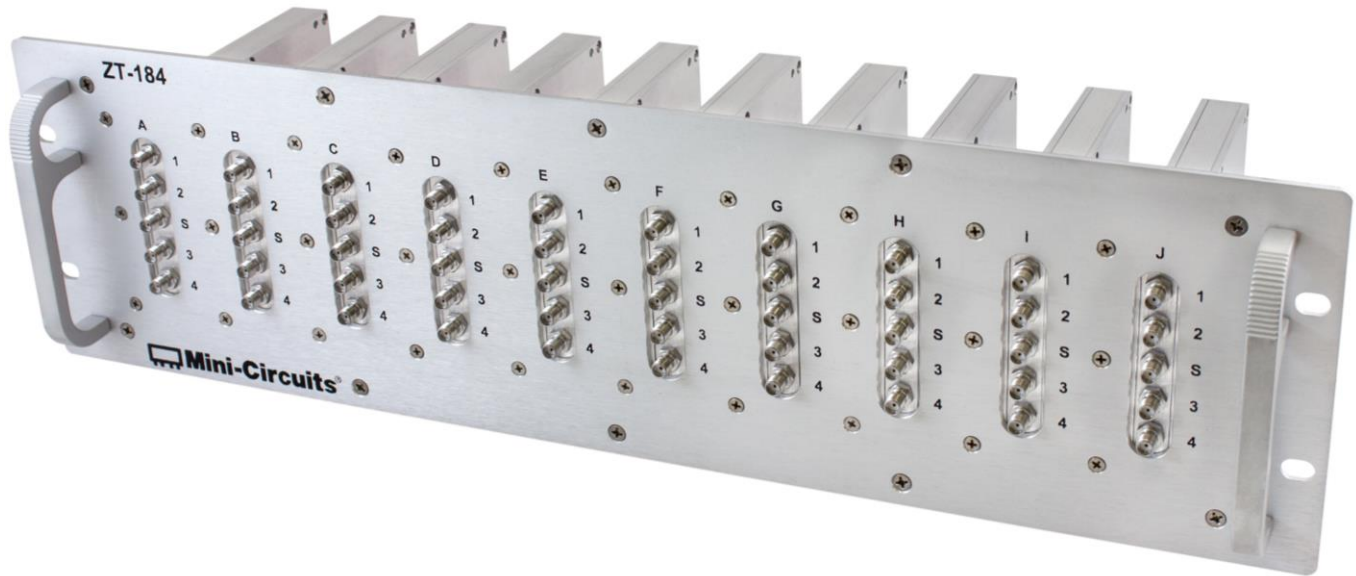

**Electrical Specifications (Per Splitter)**

Parameter	Frequency (MHz)	Min.	Typ.	Max.	Unit
Frequency		250		6000	MHz
Insertion Loss (above theoretical 6.0 dB)	250-400	—	0.4	0.8	dB
	400-3000	—	0.8	1.4	
	3000-5700	—	1.3	2.2	
	5700-6000	—	1.8	2.5	
Isolation	250-400	8	15	—	dB
	400-3000	16	22	—	
	3000-5700	18	24	—	
	5700-6000	13	17	—	
Phase Unbalance	250-400	—	0.5	3	Degree
	400-3000	—	1.5	5	
	3000-5700	—	2	6	
	5700-6000	—	3	6	
Amplitude Unbalance	250-400	—	0.1	0.3	dB
	400-3000	—	0.1	0.4	
	3000-5700	—	0.2	0.6	
	5700-6000	—	0.3	0.6	
VSWR (Port S)	250-400	—	1.20	1.7	:1
	400-3000	—	1.25	1.7	
	3000-5700	—	1.25	1.65	
	5700-6000	—	1.4	1.7	
VSWR (Port 1-4)	250-400	—	1.1	1.25	:1
	400-3000	—	1.2	1.5	
	3000-5700	—	1.2	1.45	
	5700-6000	—	1.25	1.55	